

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

---



Sleeve housing B24, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, 1x M25, height: 60 mm, cable gland: none, Standard

---

## Your advantages

- good shielding in the event of electromagnetic interference

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Commercial Data

Item number	1412788
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	B10
Product Key	BF7APB
Catalog Page	Page 634 (C-2-2019)
GTIN	4055626060545
Weight per Piece (including packing)	243.9 g
Weight per Piece (excluding packing)	243.9 g
Customs tariff number	85389099
Country of origin	PL

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Technical Data

 
### Notes

General	for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M
---------	--

### Product properties

Type	B24
Product type	Housing with locking latch
Application	Standard
No. of cable outlets	1
Type of the screw connection	1x M25
Housing type	Sleeve housing
Locking type	for single locking latch
Cable outlet	straight
Pg screw connection	none

### Dimensions

Dimensional drawing	
Width	44 mm
Height	60 mm
Length	120 mm

### Material specifications

Color	gray aluminum
Housing surface material	uncoated
Impact strength	IK08
Housing material	Die-cast aluminum, salt water resistant

### Ambient conditions

Degree of protection	IP66
	IP67
Degree of protection	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

### Mechanical properties

#### Mechanical data

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

Type of the screw connection	1x M25
Locking type	Pin

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL


1412788

<https://www.phoenixcontact.com/us/products/1412788>



## Drawings

Dimensional drawing

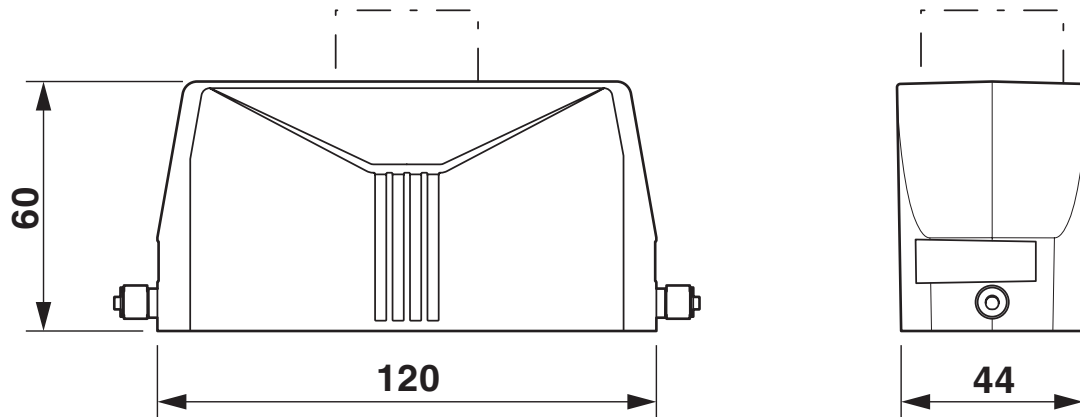

Dimensional drawing


# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL





1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Approvals

**DNV**  
Approval ID: TAE000037S

**cUL Recognized**  
Approval ID: E255026

**UL Recognized**  
Approval ID: E255026

**EAC**  
Approval ID: RU C-DE.AI30.B.01102

**EAC**  
Approval ID: RU C-DE.BL08.B.00511

**cULus Recognized**

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Classifications

### ECLASS

ECLASS-9.0	27440202
ECLASS-10.0.1	27440202
ECLASS-11.0	27440202

### ETIM

ETIM 8.0	EC000437
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------



1412788

<https://www.phoenixcontact.com/us/products/1412788>

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"



# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Accessories

### Cable gland

Cable gland - G-INS-M25-M68N-NNES-S - 1411165

<https://www.phoenixcontact.com/us/products/1411165>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 11 mm ... 17 mm, shielding: no, connecting thread: M25 x 1.5, color: silver, with O-ring

---

### Screw connection

Screw connection - WP-G HF IP66 M25 BK - 3240899

<https://www.phoenixcontact.com/us/products/3240899>



Cable gland, metric thread, IP66 protection, straight

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Cable gland

Cable gland - G-INSEC-M25-S68N-NCRS-S - 1411190

<https://www.phoenixcontact.com/us/products/1411190>



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 11 mm ... 16 mm, shielding: yes, connecting thread: M25 x 1.5, color: silver, with O-ring

---

## Screw connection

Screw connection - WP-G HF IP69K M25 BK - 3240885

<https://www.phoenixcontact.com/us/products/3240885>



Cable gland, metric thread, IP68/69k protection, straight

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Plastic label

Plastic label - US-EMLP (20X9) CUS - 0830085

<https://www.phoenixcontact.com/us/products/0830085>

Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75



---

## Screw connection

Screw connection - WP-GA HF IP66 M25 BK - 3240927

<https://www.phoenixcontact.com/us/products/3240927>

Cable gland, metric thread, IP66 protection, angled



# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Protective cover

Protective cover - HC-B24-HCLWS-PLR-BK - 1414637

<https://www.phoenixcontact.com/us/products/1414637>



Protective cover B24, with single locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm

---

## Screw connection

Screw connection - WP-GA HF IP69K M25 BK - 3240913

<https://www.phoenixcontact.com/us/products/3240913>



Cable gland, metric thread, IP68/69k protection, angled

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL

1412788

<https://www.phoenixcontact.com/us/products/1412788>



## Screw connection

Screw connection - WP-GR HF IP66 M25 BK - 3240955

<https://www.phoenixcontact.com/us/products/3240955>



Cable gland, metric thread, IP66 protection, with strain relief

---

## Screw connection

Screw connection - WP-GR HF IP69K M25 BK - 3240941

<https://www.phoenixcontact.com/us/products/3240941>



Cable gland, metric thread, IP68/69k protection, with strain relief

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Screw connection

Screw connection - WP-G PP HF M25 - 3240999

<https://www.phoenixcontact.com/us/products/3240999>

Cable gland made from PP with metric thread, IP65 protection



---

## Screw connection

Screw connection - WP-GT PP HF M25 - 3241013

<https://www.phoenixcontact.com/us/products/3241013>

Cable gland made from PP with metric thread, rotatable, IP54 protection



# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL



1412788

<https://www.phoenixcontact.com/us/products/1412788>

## Screw connection

Screw connection - WP-G BRASS IP40 M25 - 3241048

<https://www.phoenixcontact.com/us/products/3241048>



Cable gland made from brass with metric thread, IP40 protection

---

## Screw connection

Screw connection - WP-GT BRASS M25 - 3241034

<https://www.phoenixcontact.com/us/products/3241034>



Cable gland made from brass with metric thread, rotatable, IP40 protection

# Housing - HC-STA-B24-HLFS-1TTM25-EL-AL

1412788

<https://www.phoenixcontact.com/us/products/1412788>



## Screw connection

Screw connection - WP-G BRASS IP65 M25 - 3241062

<https://www.phoenixcontact.com/us/products/3241062>



Cable gland made from brass with metric thread, IP65 protection

---

Phoenix Contact 2022 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)