

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210230238](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form A-18mm, PG9 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Black, NBR Profiled Gasket and Screw, Bulk Pack, Mounted

Documents:
[Drawing \(PDF\)](#)
[Product Specification STR-1552-001 \(PDF\)](#)
[Packaging Specification PK-121023-C18-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Field Attachable / Accessories
Series [121023](#)
Form A - 18mm
IP Rating IP65
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Type Field Attachable Connector
UPC 883906248925

Physical
Cable Diameter 6.00-8.00mm
Coupling Type Internal Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polyamide
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 24.040/g
Orientation 90° Angle
Pitch - Mating Interface 18.00mm
Poles 2
Temperature Range - Operating -40°C to +90°C
Wire Size AWG 16

Electrical
Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info
Engineering Number C18209N21

Reference - Drawing Numbers
Packaging Specification PK-121023-C18-001
Product Specification STR-1552-001
Sales Drawing 1210230229-000, SD-121023-001-001

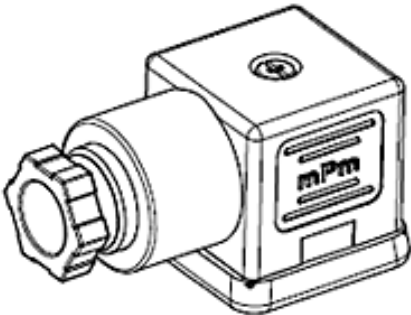

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[121023 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION