
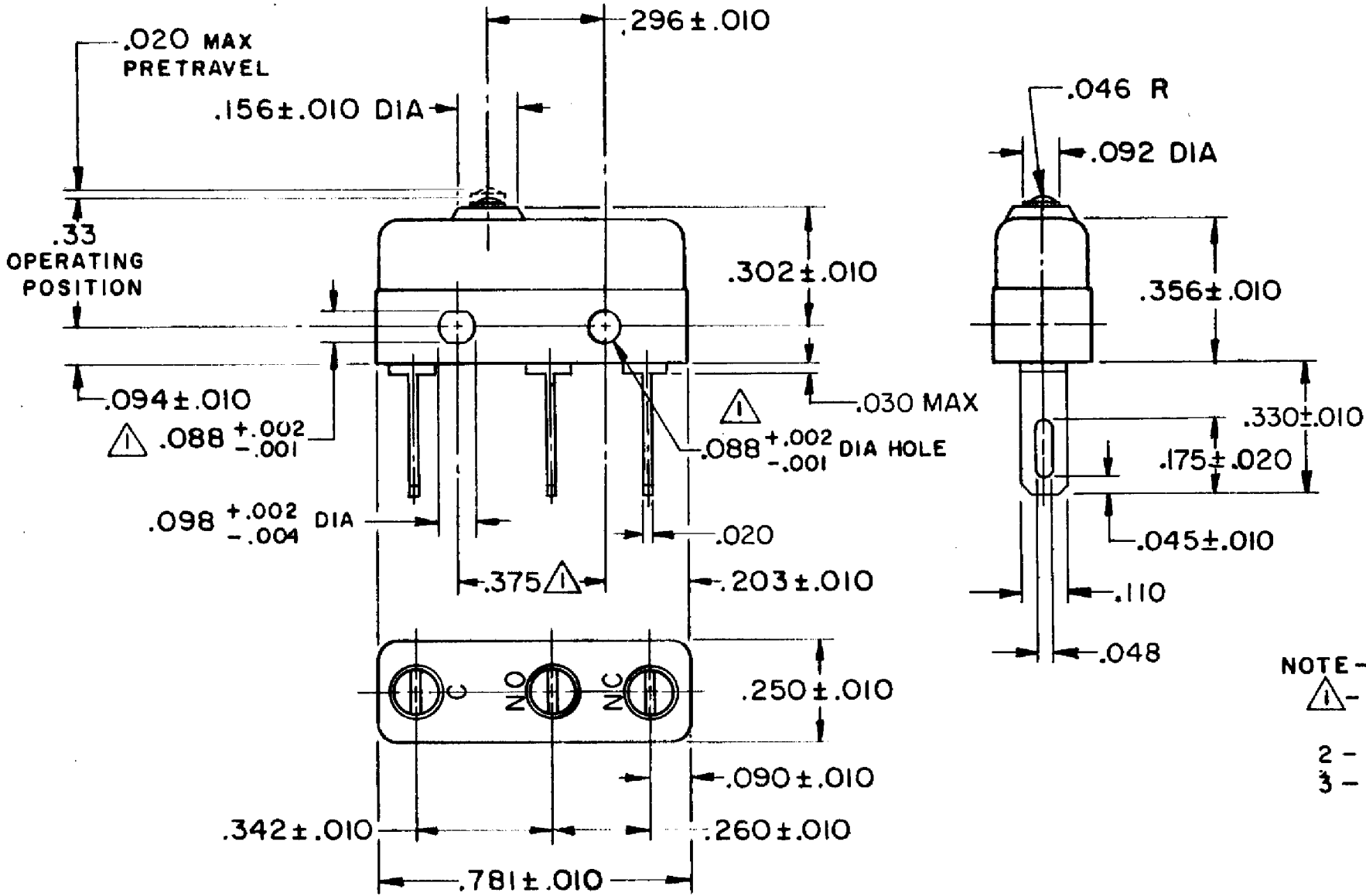


HONEYWELL PART NUMBER
11SM7601-H4
PRODUCT CODE
TWZ4500

REV	DOCUMENT	CHANGED BY	CHECK
9	0041782	PK 21JUL08	ASD

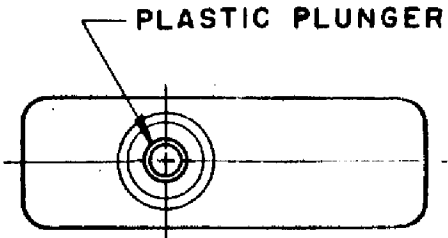

NOTE -
1 - MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF .087 MAX DIA ON .375 ± .002 CENTERS
2 - TERMINALS ARE PLATED FOR SOLDERING
3 - SWITCH WILL WITHSTAND TEMPERATURE OF 250° F

RELEASE NO.	PR - 3414
REPLACES	-

CHARACTERISTICS		ELECTRICAL DATA			DESIGN UNITS: INCH TOLERANCES UNLESS NOTED: NO PLACE X ± ONE PLACE .X ± TWO PLACE .XX ± THREE PLACE .XXX ± FOUR PLACE .XXXX ± ANGLES ± 0.030 0.015 0.005		DRAWN	VK	15 FEB 08	Honeywell				
OPERATING FORCE — — 56 GRAM MAX		CONTACT ARRANGEMENT SPDT					CHECK	RJ	15 FEB 08					
RELEASE FORCE — — — 14 GRAM MIN		30 VOLTS DC RATING			THIRD ANGLE PROJECTION 		THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE PERMISSION OF HONEYWELL.			TITLE SWITCH - BASIC				
DIFFERENTIAL TRAVEL — — — .002 MAX														
OVERTRAVEL — — — — — .005 MIN		MAXIMUM INRUSH 24 AMP					INTERPRET PER ANSI Y14.5M-1982 OTHER HONEYWELL ENGINEERING STANDARDS MAY APPLY			SIZE	TYPE	DRAWING NAME		REV
										B	I	11SM7601-H4		9
										RASTER			SCALE	-
		APPROVALS												
		UL, CSA	4A 250 VAC 1/10 HP 125 VAC 		BRAND L185									