 



Connector Type C, EN 60603, DIN 41612, Male, 32 Contacts, Solder Pins, 3 mm

CATALOG NUMBER

69001-826

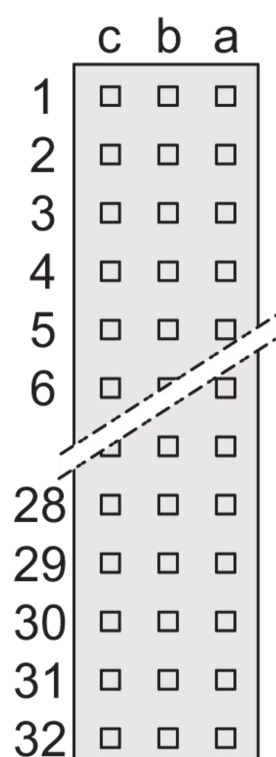

Male / Female DIN connector form C.

CERTIFICATIONS



FEATURES

Requirement class 2 as per EN 60603 (DIN 41642)

Separate coding

PRODUCT ATTRIBUTES

Type: Male Connectors
Number of Contacts: 32
Package Quantity: 1
Contact Material: Gold Plated
Max Current @ 20°C: 2A
Max Contact Resistance: 20mO
Test Voltage (Ueff), Contact-Contact: 1kV
Test Voltage (Ueff), Contact-Earth: 1.55kV
Row Assignment: A; C
Finish: Gold Plated
Product Type: Connector
Works With: Front Panels
Connection Type: Solder Pins, 3 mm

ADDITIONAL PRODUCT DETAILS

Requirement class 2 as per EN 60603 (DIN 41642).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE