


Part Number : [357607100](#)

Series Number : 35760

Status : Active - Proprietary

Product Category : Splices

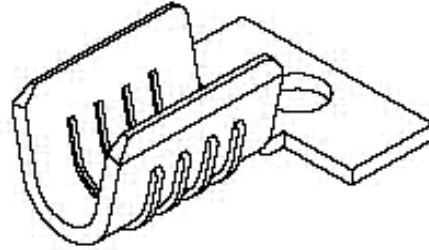


Specifications

[PK-35760-001-001.pdf](#)

[PS-35760-003-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Part Details

General

Status	Active - Proprietary
Category	Splices
Series	35760
Description	Wire Splice, 20-16 AWG, Un-Plated
Product Name	N/A
UPC	800754236645

Electrical

Voltage - Maximum	200V AC (RMS)/DC
-------------------	------------------

Physical

Barrel Type	Open
Insulation	None
Material - Metal	Brass
Net Weight	0.186/g
Packaging Type	Reel
Temperature Range - Operating	-30° to +105°C
Wire Insulation Diameter	3.51mm
Wire Size (AWG)	16, 18, 20
Wire Size mm ²	0.50-1.50

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----