


MCASE™ CARTRIDGE FUSES RATED 32V

RoHS

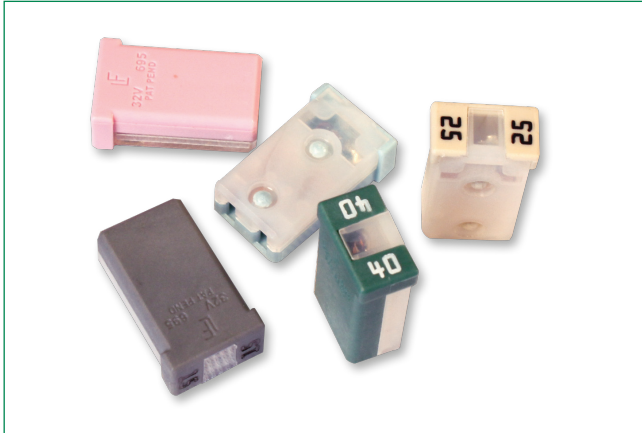

Specifications

Voltage Rating:	32 VDC
Interrupting Ratings:	1000A @ 32 VDC
Operating Temperature Range:	-40°C to +125°C
Insertion Force:	44.1N Max. (9.9 lb.) Single Terminal
Extraction Force:	4N Min. (0.9 lb.) 24.5N Max. (5.5 lb)

Ordering Information

Part Number	Package Size
0695xxx.PX4	2000
0695xxx.L	50

Description


The MCASE™ is a cartridge style fuse with female terminals for 2.8 mm male terminals. It has a miniaturized footprint for optimal usage of space. It is a time delayed fuse and can handle inrush currents.

Time-Current Characteristics

% of Rating	Opening Time Min / Max (s)
110	100 hrs / -
135	60 s / 1800 s
200	2 s / 60 s
350	0.2 s / 7 s
600	0.04 s / 1 s

Dimensions

Dimensions in mm

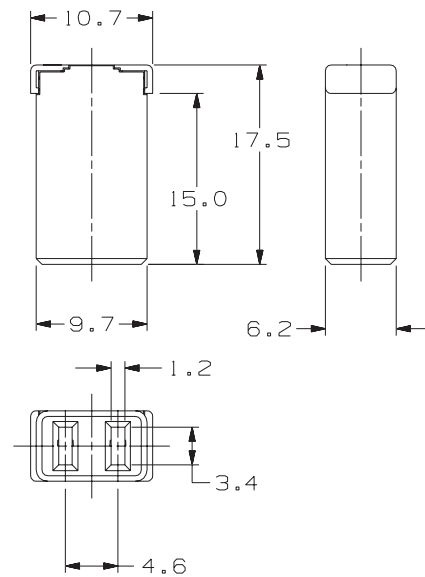

Ratings



Part Number	Current Rating	Housing Material Color	I ² t
0695015._	15 A	Grey	160 A²s
0695020._	20 A	Blue	530 A²s
0695025._	25 A	White	1140 A²s
0695030._	30 A	Pink	970 A²s
0695040._	40 A	Green	2950 A²s

MCASE™ CARTRIDGE FUSES RATED 32V


RoHS

Dimensions

Dimensions in mm

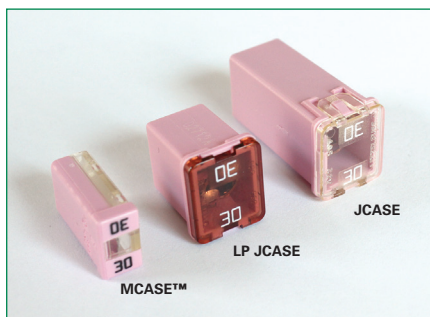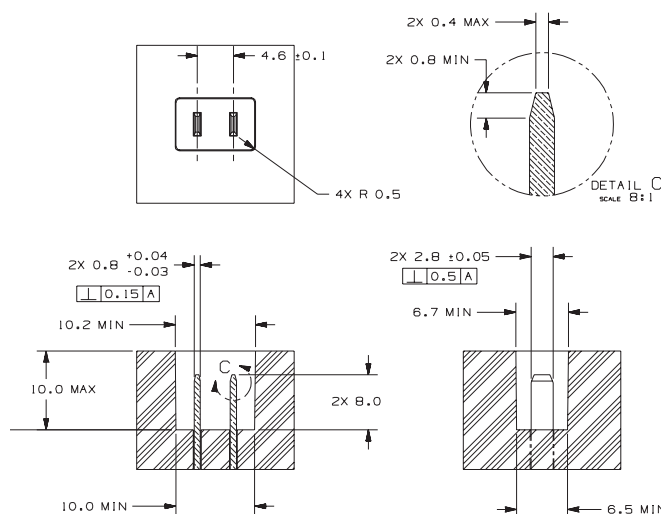

Time-Current Characteristics Curve

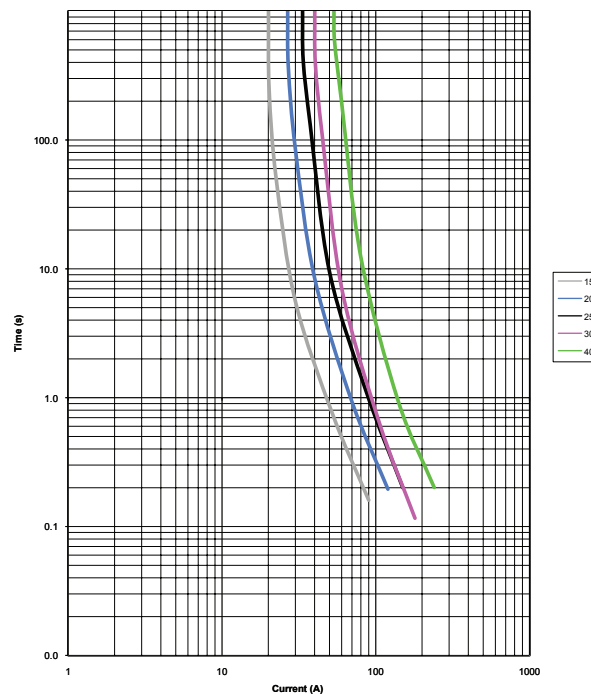

Temperature Derating Curve

