

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731100002

Status:

Active

Overview:

FCT D-Sub Connectors

Description:


FCT Standard-Density Waterproof D-Sub Connector, Female, Right-Angle, PCB Through Hole, Gold over Nickel Phosphorus Plating, Metal Watertight Frame, Snap-in Bolt, 50 Circuits

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	D-Sub Products
Series	173110
IP Rating	IP67
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056254953
Physical	
Circuits (Loaded)	50
Circuits (maximum)	50
Color - Resin	Red
Durability (mating cycles max)	500
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Brass
Net Weight	55.400/g
Number of Rows	3
Orientation	Right-Angle
PC Tail Length	12.50mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Thread-In
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.54mm
Plating - Contact	Gold over Nickel Phosphorus
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-25° to +70°C
Termination Style	Through Hole
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP67
Electrical	
Current - Maximum per Contact	7.5A
Material Info	
Engineering Number	FWDRM50S5A

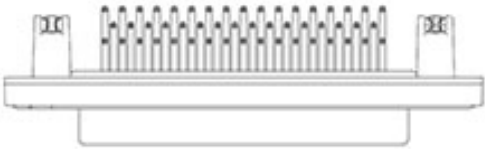

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

173110 Series

Mates With

FCT Standard Density D-Sub, Size 5, 50 Position, Plug

Use With

FCT D-Sub Dust Caps

This document was generated on 02/18/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION