



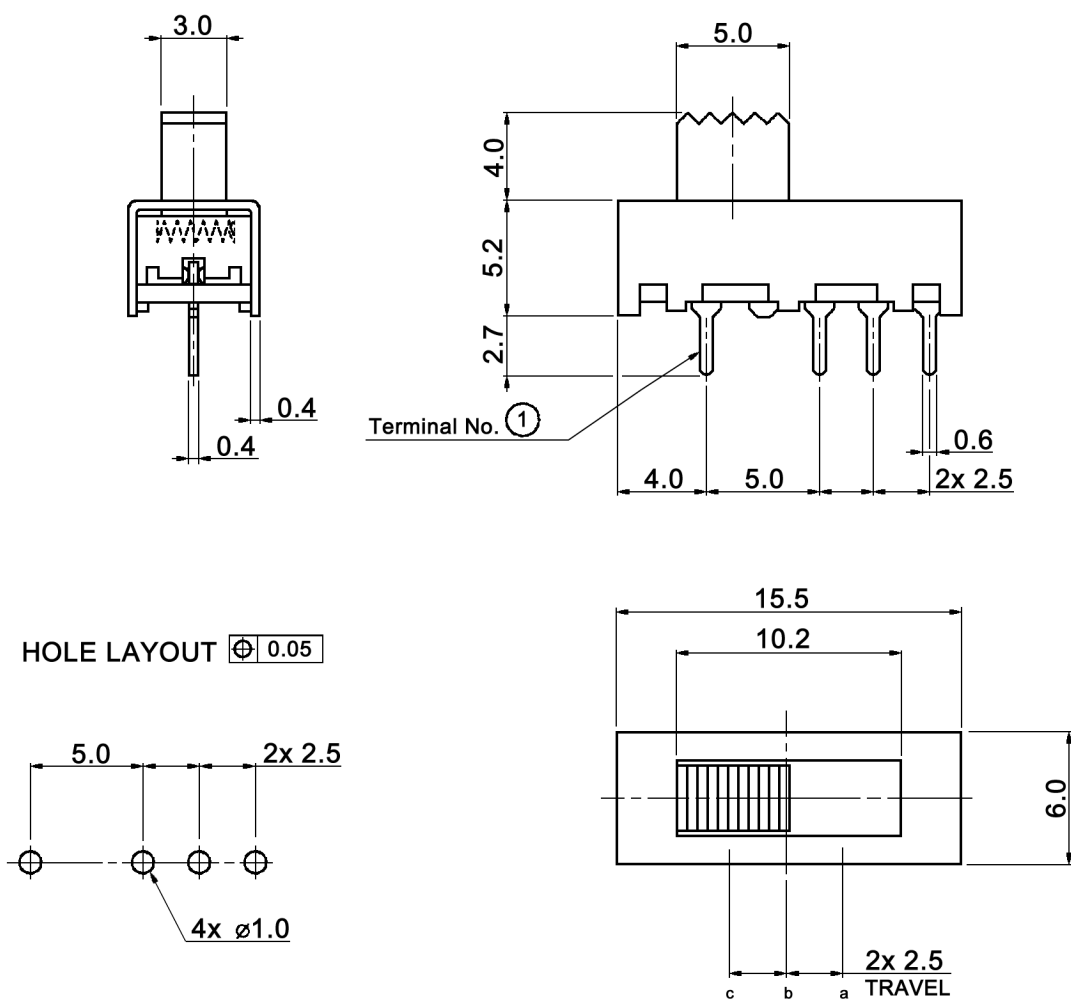

Specifications:

- Contact rating: 0.35A, 30V DC
Contact resistance: 30mOhm max.
Insulation resistance: 100MOhm min. at 500V DC for 1 minute
Dielectric strength: 500V AC (50/60Hz, 2mA) for 1 minute
Operating temperature: -10°C to +60°C
Mechanical life: 10 000 cycles
Operating force: a-b c-b: 200 +/-100gf
b-c b-a: 300 +/-150gf
Soldering conditions: 260 +/-5°C, 5 +/-1sec.
Material: Contact clip: phosphor bronze, silver plated
Steel ball: carbon steel, natural
Spring: SWC, temper
Slider: POM, black
Terminal: brass strip, silver plated
Base: phenolic resin, natural
Frame: steel, nickel plated

CIRCUIT DIAGRAM
C: COMMON PIN
BOTTOM VIEW

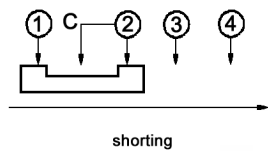

Compliance: RohS II (2011/65/EU)

Tolerances: up to 10: ±0.2mm above 10-50: ±0.3mm			Date	Name	MFP 1323	
			04/12	dr		
					30 26 13	
Modifications	Date	Name	knitter-switch			Page
						1/1