




Search within category

GO

BUY NOW

DESIGN / INSTALL

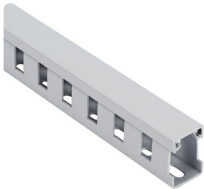

TNC25X75LG2

Type TNC slotted wall wiring duct, 24.6mm W x 72.4mm H, 6.6' length, polyphenylene ether + high impact polystyrene (PPE + HIPS), light gray, base and cover packaged together.

Specs

Packaging Details

Documents

★ Add to Favorites

🛒 Add to BOM

Material	Polyphenylene Ether + High Impact Polystyrene (PPE + HIPS)
Color	Light Gray
Type	Base and Cover
Nominal Duct Size WxH inches (mm)	25 x 75
Height (In.)	2.85
Width (In.)	0.97
Length (ft.)	6.60
Width (mm)	24.6
Length (m)	2.0
Cover Part Number	TNC25LG2 (included)
CE Compliant	Yes
CSA Certified	Yes
UL Recognized (File No. E147128)	Yes
UL recognized continuous use temp	221°F (105°C)
Cover Width (mm)	24.6
Flammability Rating	UL94 V-0, CSA certified
Mounting Method	DIN Standard Mounting Holes
Part Features	Metric Low-Smoke/Halogen-Free Wide finger and slot design provides greater rigidity and allows use with a wide range of wire and bundle sizes. Upper and lower scorelines allows easy finger and sidewall section removals. The halogen-free material is environmentally safe and will not release corrosive or toxic gases. Base and Cover Packaged together.
RoHS Compliancy Status	Compliant
Min. Order Qty.	20