

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1451320410

Status:


Active

Overview:

Micro-Fit Connector System

Description:

Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assembly, Single Row, 1.0m Length, 4 Circuits, Black

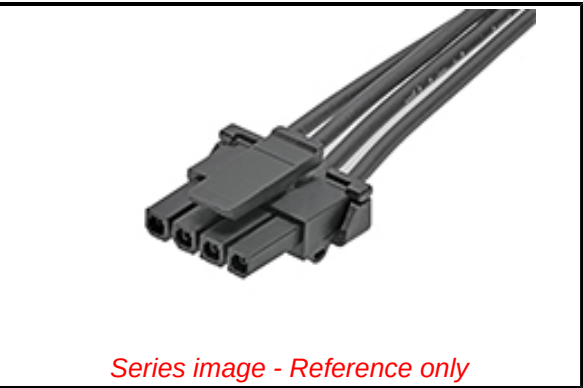

Series image - Reference only

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	145132
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Micro-Fit TPA Both Ends
Overmolded	No
Overview	Micro-Fit Connector System
Product Name	Micro-Fit TPA
Taxonomy	Power and Signal Cable Assembl
Type	Discrete Wire Assembly
UPC	191130115662
Physical	
Cable Length	1.0m
Circuits (Loaded)	4
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	28.782/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.85mm
Wire Size AWG	20
Wire/Cable Type	UL 1061
Electrical	
Current - Maximum per Contact	8.5A
Voltage - Maximum	300V AC/DC
Material Info	
Reference - Drawing Numbers	
Sales Drawing	4000095241-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained per - D(2022)9120-DC (17 Jan 2023)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

145132 Series

Mates With

Micro-Fit 3.0 Plug Housing [43640](#)

Micro-Fit TPA Plug Housing [200875](#)

Micro-Fit 3.0 Header [43650](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION