




Part Number : [310671040](#)

Product Description : 2.54mm H-DAC 64, 3 Way Male Housing Assembly, Single Row, Polarization A, Black

Series Number : 31067

Status : Active

Product Category : Connector Housings

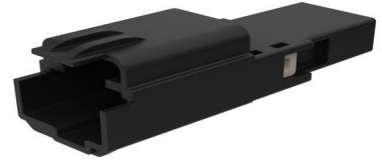

Documents and Resources

Drawings

[310671040 sd.pdf](#)

[PK-30907-737-001.pdf](#)

[PK-31301-076-001.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[AS-31067-100-001.pdf](#)

[PS-31067-0001-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Compliant |
| China RoHS | Not Relevant |
| EU ELV | Compliant per 2000/53/EC |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2025)7771-DC (04 Feb 2026) |
| EU RoHS | Compliant per EU 2015/863 |

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|---|
| Status | Active |
| Category | Connector Housings |
| Series | 31067 |
| Description | 2.54mm H-DAC 64, 3 Way Male Housing Assembly, Single Row, Polarization A, Black |
| Application | Automotive, Power, Wire-to-Wire |
| Comments | Polarization Option A, Black |
| Product Name | H-DAC 64 |
| UPC | 800756062969 |

Physical

| | |
|-----------------------|---------------------------------|
| Circuits (maximum) | 3 |
| Color - Resin | Black |
| Gender | Plug |
| Glow-Wire Capable | No |
| Keying to Mating Part | No |
| Lock to Mating Part | Yes |
| Material - Resin | Modified Polystyrene, Polyester |
| Net Weight | 1.692/g |
| Number of Rows | 1 |

| | |
|-------------------------------|----------------|
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 2.54mm |
| Pitch - Termination Interface | 2.54mm |
| Polarized to Mating Part | Yes |
| Ports | 1 |
| Stackable | No |
| Temperature Range - Operating | -40° to +100°C |

Solder Process Data

| | |
|------------------------------|-----|
| Lead-Free Process Capability | N/A |
|------------------------------|-----|

Mates With / Use With

Mates with Part(s)

| Description | Part Number |
|--|------------------|
| 2.54mm H-DAC 64, 3 Way Receptacle Assembly, Single Row, Polarization A | <u>310671010</u> |

Use with Part(s)

| Description | Part Number |
|-------------|---------------------------|
| Use With | See Product Specification |

This document was generated on Apr 15, 2026