

Part Number : [10221022](#)


Product Description : 5.08mm Pitch SPOX Crimp Housing, Female, with Friction Ramp and Void, 2 Circuits

Series Number : 5198

Status : Obsolete

Product Category : Connector Housings

Engineering Part Number : 5198-02

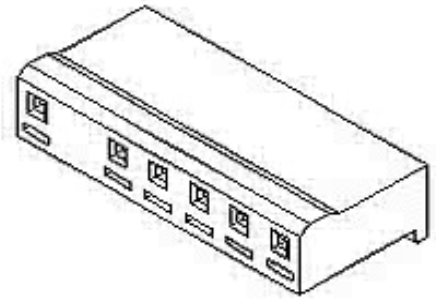

Documents and Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Part Details

General

Status	Obsolete
Category	Connector Housings
Series	5198
Description	5.08mm Pitch SPOX Crimp Housing, Female, with Friction Ramp and Void, 2 Circuits
Application	Signal
Product Name	SPOX
UPC	800754315425

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	1171.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
SPOX 5.08mm Pitch Vertical Single Row Headers	<u>5285</u>

Use with Part(s)

Description	Part Number
SPOX Female Crimp Terminals	<u>5194</u>

This document was generated on Apr 29, 2026

Obsolete