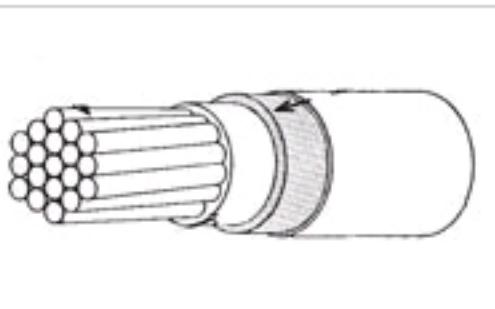


55FA0514-24-7L Product Details

[Share](#) [Print](#) [Email](#)

Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

55FA0514-24-7L
TE Internal Number: 024311-000
Product Highlights [View All](#)

- Cable Type = Spec 55F
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)
Please Note:
Use the Product Drawing for all design activity
Product Type Features
Cable Type  Spec 55F

Cable Style  Primary

Electrical Characteristics
Voltage Rating (VAC) 600

Body Features
Wire Size (AWG/CM) 24 AWG

Cable Jacket Color Violet 
Conductor Type Tin-Coated Copper

Wire Color Violet

Nominal Outside Diameter (mm [in]) 2.13 [0.084]

Wire Diameter (mm [in]) 0.64 [0.025]

Configuration Features
Number of Conductors 1

Industry Standards
Government/Industry Qualification  No

RoHS/ELV Compliance  Not ELV/RoHS compliant

Lead Free Solder Processes  Not relevant for lead free process

Conditions for Usage
Temperature Range (°C) 150

Operation/Application
Application General Purpose - Light Weight

Packaging Features
Wire Source United States

Other
Brand Raychem

Node Classification Hook Up Wire

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)
[View Part in Product Feature Selector](#)
[Check for Tooling](#)
Corporate Information
[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)
Quick Links
[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)
Customer Support
[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)
Keep Me Informed
