

IT 3057-XXC General Duty Cable Clamp for Jacketed or Multipolar Cable or Wires Protected by Tubing



ITH
Rigid Insert
Connectors

IT 3057-10C F2

MIL-C-5015 Compatible
Accessory

Basic Part Number
and Shell Size Designator
(Table I)

Finish Options (Table II)

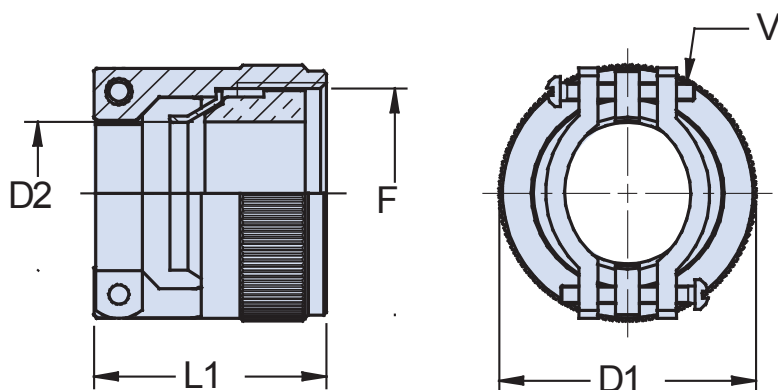


TABLE II: MODIFICATION CODES

FINISH OPTIONS	
Sym	Description
F2	Bright Nickel Plating
F6	Black Electrodeposited Paint
F8	Olive Drab Zn-Co Plating
Omit for standard version (See Note 2)	

TABLE I: PART NUMBER AND CONNECTOR SIZE DESIGNATOR

Part Number	Shell size	Sleeve	A	B		F thread	L	V thread
				min.	Max.			
IT 3057-10C	18	IT 3420 - 6A / 10A	31.0	9.60	15.87	1.0000 - 20UNEF	35.3	6 - 32NC
IT 3057-12C	20 - 22	IT 3420 - 8A / 12A	37.3	11.30	19.00	1.1875 - 18UNEF	35.7	8 - 32NC
IT 3057-16C	24 - 28	IT 3420 - 8A / 12A / 16A	42.0	15.50	23.80	1.4375 - 18UNEF	38.5	8 - 32NC
IT 3057-20C	32	IT 3420 - 12A / 16A / 20A	54.0	23.40	31.75	1.7500 - 18UNS	44.8	250 - 20NC
IT 3057-24C	36	IT 3420 - 16A / 18A / 24A	57.1	23.40	35.00	2.0000 - 18UNS	51.6	250 - 20NC
IT 3057-28C	40	IT 3420 - 16A / 20A / 28A	63.5	29.90	41.25	2.2500 - 16UN	51.6	250 - 20NC

Application Notes:

- General duty cable clamp suitable for jacketed or multipolar cable or wires protected by tubing.
- Standard materials configuration consists of aluminum alloy with cadmium free conductive finish and black passivation.
- Other types of front and rear connector accessories are available.
See our website and/or contact the factory for complete information.