

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191930264
Status: Active
Overview: VersaKrimp Terminals and Splices
Description: VersaKrimp Ring Tongue Terminal for 4 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19193
Crimp Quality Equipment Yes
Overview VersaKrimp Terminals and Splices
Product Name VersaKrimp
Type Ring
UPC 800753040564

Physical
Barrel Type Closed - Brazed
Insulation None
Material - Plating Mating Tin
Net Weight 9.380/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 3/8" (M9)
Termination Interface: Style Crimp or Compression
Wire Size AWG 4

Material Info
Engineering Number F-366-38

Reference - Drawing Numbers
[Product Specification](#) PS-19902-011-001, PS-19902-013-001
[Sales Drawing](#) 191930254-000

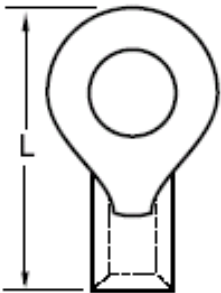

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - D(2020)4578-DC (25 June 2020) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
---	--

Search Parts in this Series
19193 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Manual Putt Pump Hydraulic System, Die set required	192860117
Die Set (large) for the HHLS Hydraulic Crimper	192900007
Manual tool for Crimping non-insulated 8AWG thru 4/0 Terminals	192940008
Hydraulic Dieless Crimping Tool	638161700
Square "DIN" style dies for 4 AWG	640037870

This document was generated on 10/29/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION