



ebm-papst St. Georgen GmbH & Co. KG
Hermann-Papst-Str. 1
D-78112 St. Georgen
Phone +49 (0) 7724 81-0
info2@de.ebmpapst.com
www.ebmpapst.com

Nominal data


Item	8500 A	
Motor	-0	
Phase		1~
Nominal voltage	VAC	115
Frequency	Hz	60
Speed (rpm)	min ⁻¹	3200
Power consumption	W	11.0
Min. ambient temperature	°C	-10
Max. ambient temperature	°C	75
Air flow	m ³ /h	57
Sound power level	B	5.5
Sound pressure level	dB(A)	41

ml = Max. load · me = Max. efficiency · fa = Free air · cs = Customer specification · ce = Customer equipment
Subject to change

Technical description

Weight	0.49 kg
Dimensions	80 x 80 x 38 mm
Impeller material	Metal
Housing material	Metal
Airflow direction	Intake over struts
Service life L10 at 40 °C	55000 h
Service life L10 at maximum temperature	25000 h
Option	Optionally available with electrical hookup to leads. Optionally available with exhaust over struts and clockwise rotation.

Product drawing

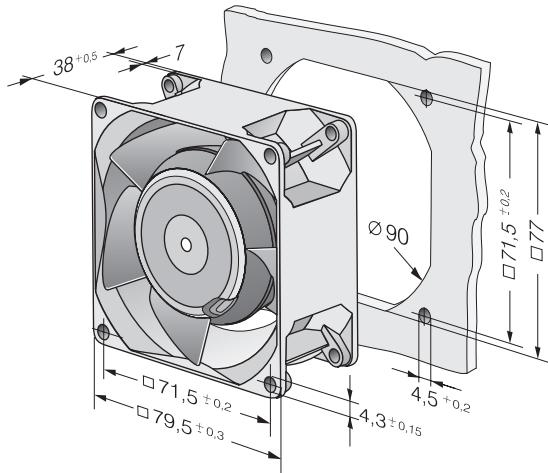

Curves: Air performance

