


COAXIAL CONNECTOR, MCX, 50 Ohm, Right angle cable plug (male)
16_MCX-50-1-11/111_N

Properties

- Small size
- Easy to connect and disconnect
- Wide range of board connectors and cable connectors available

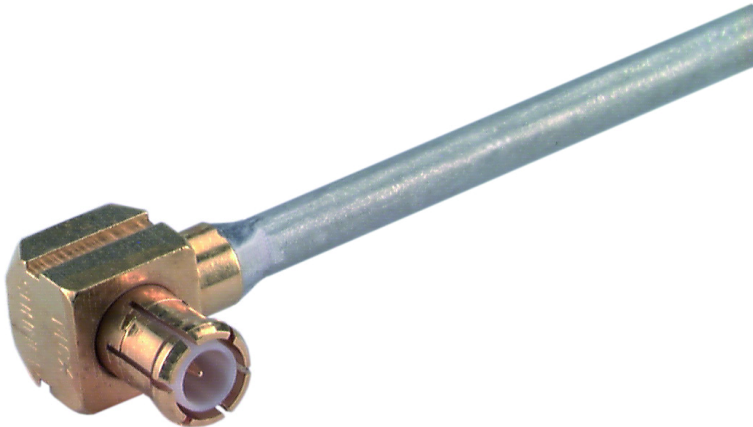

Product configuration		
Interface type	Gender	Standard
MCX	plug	IEC 60169-36_CECC 22220
Interface and material data		
Piece parts	Material	Plating
Centre contact	Brass	Gold Plating (Nickel underplated)
Outer conductor	Copper Beryllium Alloy	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	
Electrical data		
Impedance		50 Ω
Interface frequency		6 GHz
Mechanical data		
Weight		0.000773 kg
Mating cycles		500
Cable entry centre contact		soldered
Cable entry outer contact		soldered
Environmental data		
Operation temperature		-65 °C ... 165°C

COAXIAL CONNECTOR, MCX, 50 Ohm, Right angle cable plug (male)

16_MCX-50-1-11/111_N

Ordering Information Table		
Item number	Item description	Packaging type
23024700	16_MCX-50-1-11/111_NE	Single
23032063	16_MCX-50-1-11/111_NH	Bulk 100 pcs

Suitable cables	
Cable group	Y2 - 1 mm / 50 Ohm
	Y15 - 1 mm / 50 Ohm
Suitable cables	SR_47_TP_M17
	SUCOFORM_47_CU

Additional Information	
Only as assembly	No

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P3137 / Date of publication: 25.11.2023 / uncontrolled copy