


Search within category

GO

BUY NOW

DESIGN / INSTALL

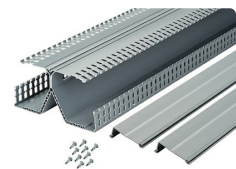

DRD44WH6

Panduit® PanelMax,® DIN rail wiring duct (base, covers and DIN rail fasteners), 4 height, PVC, white.

Specs	Packaging Details	Documents	★ Add to Favorites	🛒 Add to BOM
Material	Lead-Free PVC			
Color	White			
Height (In.)	4.16			
Height (mm)	105.7			
Type	Base and Cover			
Width (In.)	8.25			
Width (mm)	209.6			
Length (ft.)	6.00			
Length (m)	1.8			
Cover Part Number	DRDC4WH6 (included)			
CE Compliant	Yes			
CSA Certified	Yes			
UL Recognized (File No. E147128)	Yes			
UL recognized continuous use temp	122°F (50°C)			
Flammability Rating	UL94 V-0			
Mounting Method	Standard Mounting Holes			
Nominal Duct Size W x H (In.)	Compatible with standard 4 Height Wiring Duct			
Part Features	2-Channel Wiring duct with a hinged and flexible cover that allows you to mount DIN Rail and components on top of the duct to maximize space. Up to 30% panel Space savings, up to 25% material cost savings, and up to 50% faster installation. Pass thru holes to shorten the wire path			
RoHS Compliancy Status	Compliant			
Min. Order Qty.	6			