



Part Number : [192020035](#)


Product Description : NylaKrimp Butt Splice for 16-14 AWG Wire, Tape and Reel

Series Number : 19202

Status : Active

Product Category : Splices

Engineering Part Number : BS-N-331T

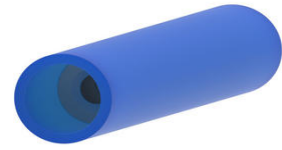

Documents and Resources

Drawings

[192020035_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Splices
Series	19202
Description	NylaKrimp Butt Splice for 16-14 AWG Wire, Tape and Reel
Product Name	NylaKrimp
Style	Standard
Type	Butt Splice
UPC	800753047907

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed - Brazed
Color - Resin	Blue
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.328/g

Packaging Type	Adhesive Tape on Reel
Wire Size (AWG)	14, 16

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880098</u>

This document was generated on May 21, 2026