

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300470039

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) PROFINET Field Attachable Connector, 4 Poles, D-Coded, Straight, Male, Shielded, IDC Termination, Cable Diameter 4.00-8.00mm

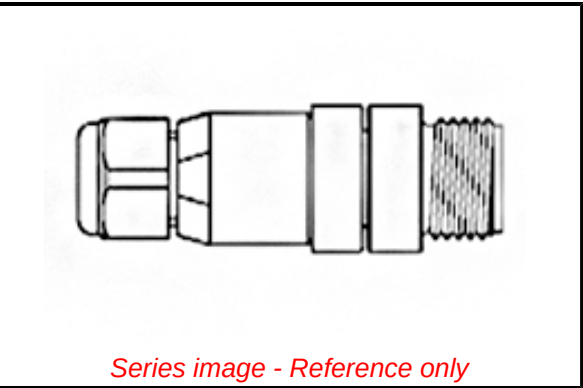

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Field Attachable / Accessories
Series	130047
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Type	Field Attachable Connector
UPC	889056509961
Physical	
Cable Diameter	4.00-8.00mm (.157-.315")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	D-coded
Material - Connector Body	Zinc Die-Cast
Material - Coupling Nut	Zinc Die-Cast, Nickel-Plated
Material - Plating Mating	Gold
Net Weight	40.823/g
Orientation	Straight
Poles	4
Temperature Range - Operating	-40°C to +85°C
Wire Size AWG	22-26
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V
Material Info	
Engineering Number	E1AS06-53
Reference - Drawing Numbers	
Sales Drawing	1300470039-000

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130047 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION