




For case height [U]	261.8
Thickness mm	2.5
Height U	6
Width HP	4

Delivery Comprises:

Item	Quantity	Description
1	1	Front panel, U profile, Al, front anodised, rear conductive, 2 alignment pins pressed-in, stainless steel

Accessories

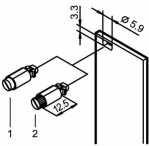

Quarter-turn fastener with slotted head, black, PU 100 pcs

21101-848


Add Item to Project List +



Sleeve, brass, black, PU 100 pcs

21100-886


Add Item to Project List +

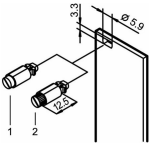

Quarter-turn fastener with knurled and slotted head, black, PU 100 pcs

21101-850

Add Item to Project List +

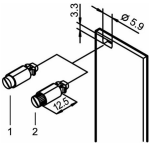

Quarter-turn fastener with knurled and slotted head, grey, PU 100 pcs

21101-849


Add Item to Project List +



Collar screw, cross recess/slotted (M2.5x12.3), steel nickel plated, PU 100 pcs

21101-101


Add Item to Project List +

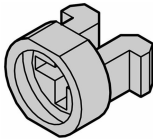

Sleeve, plastic, grey, PU 100 pcs

21100-464

Add Item to Project List +

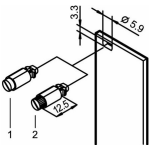

Quarter-turn fastener with slotted head, grey, PU 100 pcs

21101-847

Add Item to Project List +



Sleeve, stainless steel, PU 100 pcs

21100-662


Add Item to Project List +



Sleeve, brass nickel-plated, PU 100 pcs

21100-660


Add Item to Project List +

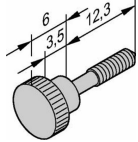

Collar screw, knurled head short (M2.5x12.3),
brass nickel plated, PU 100 pcs

21101-
749

[Add Item to Project List](#) +

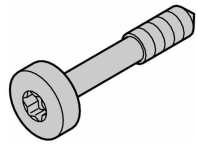

Collar screw, Torx (M2.5x12.3), steel black, PU
100 pcs

21101-
783


[Add Item to Project List](#) +



Collar screw, cross recess/slotted (M2.5x12.3),
steel black, PU 100 pcs

21101-
102


[Add Item to Project List](#) +

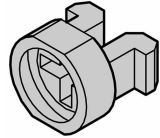

Sleeve, plastic, black, PU 100 pcs

21100-
591


[Add Item to Project List](#) +

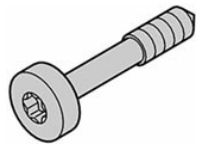

Collar screw, Torx (M2.5x12.3), steel nickel
plated, PU 100 pcs

21101-
782


[Add Item to Project List](#) +

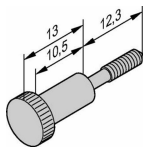

Collar screw, knurled head long for LD
(M2.5x12.3), brass nickel plated, PU 100 pcs

21101-
909

 
[Add Item to Project List](#) +



EMC shielding textile gasket, -40...+70°C, 6 U,
PU 10 pcs

21101-
855

 [Add Item to Project List](#) +



EMC shielding textile gasket, -40...+70°C, 6 U,
PU 100 pcs

21101-
856

[Add Item to Project List](#) +

EXPLORE

[About Us](#)
[Services & Capabilities](#)
[News & Events](#)
[Newsletter Subscriptions](#)
[Strategic Partnerships](#)
[Investor Relations](#)

CONTACT

[Customer Service](#)
[Find a Sales Office or Distributor](#)
[Global Locations](#)
[Product Compliance & Certifications](#)
[Partner Login](#)

DOWNLOAD

[Download Center](#)
[Reference Projects](#)
[Videos](#)
[Product Configurators](#)
[Warranties and Terms of Sale & Procurement](#)

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

