


ACCLIMATE™

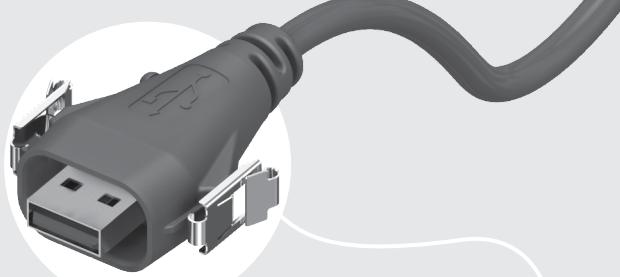

RCU-G-02.00-AMS-AM

RCU SERIES

IP68 SEALED USB CABLE PLUG

SPECIFICATIONS

For complete specifications
see www.samtec.com/?RCU

Insulator Material:
Glass Filled Thermoplastic

Contact Material:

Phosphor Bronze

Current Rating:

4.2 A per pin
(1 pin powered)

Operating Temp Range:

-20 °C to +80 °C

Shield Material:

Phosphor Bronze

Wire:

20 AWG (Power)

25 AWG (Signal)

28 AWG (Drain)

Mates with:
RPCU, RPBU

DUST CAPS

-AMS = DCA-RCU-01-01-A
-BMS = DCA-RCU-01-01-B

ALSO AVAILABLE (MOQ Required)

- Other wire lengths
- End option 2 with -AMS, -BMS or -BM

