




Quality Products. Service Excellence.

## Vertical Basic PDU 1585-6-7-8 Series

15A | 120V Single-Phase | 5-15R Outlets

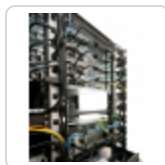

### Features

- Low-profile slim design constructed of rugged lightweight aluminum.
- It can also be used horizontally on your workbench.
- Each outlet strip includes a hardware mounting kit. Order P/N: **1585CLIP** for additional hardware kit.
- Receptacles are 1" square and are equally spaced over the length of the power strip.
- Available with a rocker switch or power indicator light and 15 Amp circuit breaker.

### Specifications

- Heavy duty 14 gauge wire cord - 14/3 SJT type for extreme temperature ranges and integral moulded plug.
- Plug types available are NEMA 5-15P straight blade or NEMA L5-15P locking type.
- Rated 15 amps, 120 volts.
- UL/cUL Listed Standard UL1363, CSA C22.2 No. 308-14 and CSA C22.2 No. 0.4-04
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America.

### Surge Specifications

- Max Energy (Joules) is 1080 J.
- 25000 Amp-rated MOV's for 75,000 Amps of single pulse transient current.
- Voltage Protection Rating (Vpr) of 500V in all three modes (L-N, L-G, N-G).
- Nominal Discharge Current (In) of 5kA.
- Voltage suppression at the outlet guards against transients from the equipment on the outlet strip.
- The green indicator light confirms surge module is active.
- Internal protection will disconnect the surge module at the end of its useful life (and extinguish the green light) but will maintain power to the load, now unprotected.
- cULus Listed to UL 1449 & C22.2 No. 269.3-17, for Surge Protective Devices – Type 3.
- cULus Listed to UL 1363 & C22.2 No. 308-18, for Relocatable Power Taps & Multi Outlet

### Plug Types



5-15P Straight Blade



L5-15P Locking Type

### Accessories

- Vertical Outlet Strip Mounting Clip Kit

Part No. On-Off Switch	Part No. Pilot Light	Strip Length	Number of Outlets	Cord Length (ft)	Color	NEMA Plug Type	Surge Protected
15851H6A1	15851T6A1	18.00	6	6	Natural	5-15P	No
15851H6C1	15851T6C1	18.00	6	6	Natural	L5-15P	No
15851H6B1	15851T6B1	18.00	6	15	Natural	5-15P	No
15851H6D1	15851T6D1	18.00	6	15	Natural	L5-15P	No
15852H6A1	15852T6A1	24.00	6	6	Natural	5-15P	No
15852H6C1	15852T6C1	24.00	6	6	Natural	L5-15P	No
15852H6B1	15852T6B1	24.00	6	15	Natural	5-15P	No
15852H6D1	15852T6D1	24.00	6	15	Natural	L5-15P	No
15852H8A1	15852T8A1	24.00	8	6	Natural	5-15P	No
15852H8C1	15852T8C1	24.00	8	6	Natural	L5-15P	No
15852H8B1	15852T8B1	24.00	8	15	Natural	5-15P	No
15852H8D1	15852T8D1	24.00	8	15	Natural	L5-15P	No
15853H6A1	15853T6A1	36.00	6	6	Natural	5-15P	No
15853H6C1	15853T6C1	36.00	6	6	Natural	L5-15P	No
15853H6B1	15853T6B1	36.00	6	15	Natural	5-15P	No
15853H6D1	15853T6D1	36.00	6	15	Natural	L5-15P	No
15853H12A1	15853T12A1	36.00	12	6	Natural	5-15P	No
15854H7A1	15854T7A1	42.00	7	6	Natural	5-15P	No
15854H7C1	15854T7C1	42.00	7	6	Natural	L5-15P	No
15854H7B1	15854T7B1	42.00	7	15	Natural	5-15P	No
15854H7D1	15854T7D1	42.00	7	15	Natural	L5-15P	No
1585H8A1	1585T8A1	48.00	8	6	Natural	5-15P	No
1585H8A1BK	1585T8A1BK	48.00	8	6	Black	5-15P	No
1585H8A1S	1585T8A1S	48.00	8	6	Natural	5-15P	Yes
1585H8C1	1585T8C1	48.00	8	6	Natural	L5-15P	No
1585H8B1	1585T8B1	48.00	8	15	Natural	5-15P	No
1585H8B1BK	1585T8B1BK	48.00	8	15	Black	5-15P	No
1585H8B1S	1585T8B1S	48.00	8	15	Natural	5-15P	Yes
1585H8D1	1585T8D1	48.00	8	15	Natural	L5-15P	No
1585H10A1	1585T10A1	48.00	10	6	Natural	5-15P	No
1585H10A1S	1585T10A1S	48.00	10	6	Natural	5-15P	Yes
1585H10C1	1585T10C1	48.00	10	6	Natural	L5-15P	No
1585H10B1	1585T10B1	48.00	10	15	Natural	5-15P	No
1585H10B1S	1585T10B1S	48.00	10	15	Natural	5-15P	Yes
1585H10D1	1585T10D1	48.00	10	15	Natural	L5-15P	No
1585H11A1	1585T11A1	48.00	11	6	Natural	5-15P	No
1585H11C1	1585T11C1	48.00	11	6	Natural	L5-15P	No
1585H11B1	1585T11B1	48.00	11	15	Natural	5-15P	No
1585H11D1	1585T11D1	48.00	11	15	Natural	L5-15P	No
1585H15A1	1585T15A1	48.00	15	6	Natural	5-15P	No
1585H15A1S	1585T15A1S	48.00	15	6	Natural	5-15P	Yes
1585H15C1	1585T15C1	48.00	15	6	Natural	L5-15P	No
1585H15B1	1585T15B1	48.00	15	15	Natural	5-15P	No
1585H15B1S	1585T15B1S	48.00	15	15	Natural	5-15P	Yes
1585H15D1	1585T15D1	48.00	15	15	Natural	L5-15P	No
1585H16A1	1585T16A1	48.00	16	6	Natural	5-15P	No
1585H16C1	1585T16C1	48.00	16	6	Natural	L5-15P	No
1585H16B1	1585T16B1	48.00	16	15	Natural	5-15P	No
1585H16D1	1585T16D1	48.00	16	15	Natural	L5-15P	No
1586H10A1	1586T10A1	60.00	10	6	Natural	5-15P	No
1586H10C1	1586T10C1	60.00	10	6	Natural	L5-15P	No

Part No.	Part No.	Strip	Number	Cord	NEMA	Surge
On-Off Switch	Pilot Light	Length	of Outlets	Length (ft)	Plug Type	Protected
1586H10B1	1586T10B1	60.00	10	15	Natural	No
1586H10D1	1586T10D1	60.00	10	15	Natural	No
1586H12A1	1586T12A1	60.00	12	6	Natural	No
1586H12A1BK	1586T12A1BK	60.00	12	6	Black	No
1586H12C1	1586T12C1	60.00	12	6	Natural	No
1586H12B1	1586T12B1	60.00	12	15	Natural	No
1586H12B1BK	1586T12B1BK	60.00	12	15	Black	No
1586H12D1	1586T12D1	60.00	12	15	Natural	No
1586H20A1	1586T20A1	60.00	20	6	Natural	No
1587H10A1	1587T10A1	70.00	10	6	Natural	No
1587H10A1BK	1587T10A1BK	70.00	10	6	Black	No
1587H10C1	1587T10C1	70.00	10	6	Natural	No
1587H10B1	1587T10B1	70.00	10	15	Natural	No
1587H10B1BK	1587T10B1BK	70.00	10	15	Black	No
1587H10D1	1587T10D1	70.00	10	15	Natural	No
1587H11A1	1587T11A1	70.00	11	6	Natural	No
1587H11A1S	1587T11A1S	70.00	11	6	Natural	Yes
1587H11C1	1587T11C1	70.00	11	6	Natural	No
1587H11B1	1587T11B1	70.00	11	15	Natural	No
1587H11B1S	1587T11B1S	70.00	11	15	Natural	Yes
1587H11D1	1587T11D1	70.00	11	15	Natural	No
1587H12A1	1587T12A1	70.00	12	6	Natural	No
1587H12C1	1587T12C1	70.00	12	6	Natural	No
1587H12B1	1587T12B1	70.00	12	15	Natural	No
1587H12D1	1587T12D1	70.00	12	15	Natural	No
1587H19A1	1587T19A1	70.00	19	6	Natural	No
1587H19A1S	1587T19A1S	70.00	19	6	Natural	Yes
1587H19C1	1587T19C1	70.00	19	6	Natural	No
1587H19B1	1587T19B1	70.00	19	15	Natural	No
1587H19B1S	1587T19B1S	70.00	19	15	Natural	Yes
1587H19D1	1587T19D1	70.00	19	15	Natural	No
1587H24A1	1587T24A1	70.00	24	6	Natural	No
1587H24C1	1587T24C1	70.00	24	6	Natural	No
1587H24B1	1587T24B1	70.00	24	15	Natural	No
1587H24D1	1587T24D1	70.00	24	15	Natural	No
1588H12A1	1588T12A1	77.00	12	6	Natural	No
1588H12A1BK	1588T12A1BK	77.00	12	6	Black	No
1588H12A1S	1588T12A1S	77.00	12	6	Natural	Yes
1588H12C1	1588T12C1	77.00	12	6	Natural	No
1588H12B1	1588T12B1	77.00	12	15	Natural	No
1588H12B1BK	1588T12B1BK	77.00	12	15	Black	No
1588H12B1S	1588T12B1S	77.00	12	15	Natural	Yes
1588H12D1	1588T12D1	77.00	12	15	Natural	No

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.