

PRODUCT TOP

CATEGORY

SPECIFICATIONS


INDUSTRIES

SERIES NAME

Enter Keyword, Product name or HRS code.

SEARCH

Product Top > DF3 series > DF3EA-13P-2H(50)

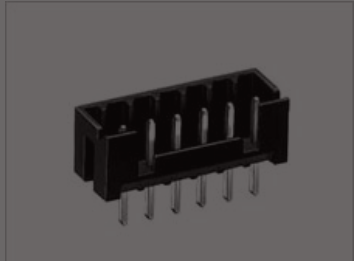

Detailed Specifications

RoHS

- ▶ Product Numbers by Series
- ▶ Find Mating Connectors
- ▶ Part Number Configuration

DF3EA-13P-2H(50)

Product	DF3EA-13P-2H(50)
Series	DF3
Connector Type	Header
Industry Standard	JIS, IEC
Number of Positions	13
Number of Rows (Interface)	1

Detailed Specifications

Last Updated On Dec. 9, 2016

▼ Product information	
Part No.	DF3EA-13P-2H(50)
CL No.	CL0543-0340-0-50
▼ Basic information	
Connector Type	Header
Industry Standard	JIS, IEC
Number of Positions	13
Number of Rows (Interface)	1
Mounting Pitch	2 mm
Contact Pitch	2 mm
Rated Current	3 A
Rated Voltage (AC)	AC 250 V
Rated Voltage (DC)	DC 250 V
Mating/Unmating Cycles	50
Mounting Style	SMT
Connector Orientation	Right angle
Downloaded from Arrow.com	

Download

 DRAWING(3D)

▶ more

ADD TO MY LIST

▼

REQUEST FOR SAMPLE

CONTACT US


CHECK STOCK

 Print this page

✉ Send this page

✉ Send this page

Browsing History

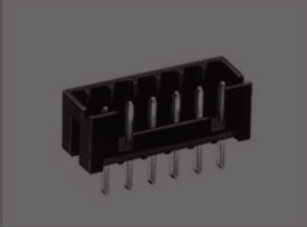

Series: DF3

Product: DF3EA-13P-2H(50)

Contact Plating	Gold
Operating Temperature	105 to -55 °C
Glow Wire Compliant	Yes
▸ Mechanical Specifications	
▸ Electrical Specifications	
▸ Dimensional Information	
▸ Packaging Specifications	

Download

Catalog	Product Series Catalog	 DOWNLOAD
Data Sheet	Drawing (2D)	Not Available  CONTACT
	3D Model (IGES)	 DOWNLOAD
	3D Model (STEP)	 DOWNLOAD
	Specification Sheet	Not Available  CONTACT

*I need help with a product or information

- [Product Top](#)[Global Site](#)
- [About Us](#)[Terms of use](#)
- [Specifications](#)
- [Industry](#)
- [Series Name](#)
- [Partners](#)

SUPPORT

- [FAQ](#)
- [CONTACT US](#)



© 1999-2017 HIROSE ELECTRIC CO., LTD. All Rights Reserved.

