

main menue



home
test & measurement
products
skills
download

online catalogue T&M

clamp-type test probes
crocodile clips
test probes
oscilloscope test probes
measuring leads
plugs
sockets
 ▶ 2 mm system
 ▶ 2 mm safety system
 ▶ 4 mm system
 ▶ 4 mm safety system
sets
miscellaneous

company

portrait
corporate association
location maps
fairs and exhibitions
jobs
imprint
terms and conditions

Home ▶ sockets ▶ 4 mm safety system ▶ sockets ▶ 4 mm safety system ▶ KB 2


KB 2

datasheet for KB 2
article number: 930584101



[View Full-Size Image](#)

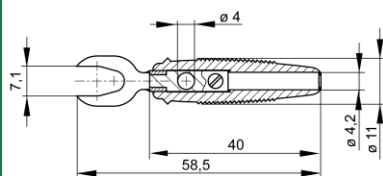

product description:		order number: 930 584-101
description:		Cable lug with shatter-proof, flexible insulated sleeve with 4 mm diameter transverse hole. Screw connection up to a maximum of 2.5 mm². For connection to bolts from 4 mm to 7 mm diameter. Nickel-plated brass contact material.
typ:		KB 2 rot/red
system:		4mm system
order number:		930 584-101
color		
other color versions:		 
technical data		
measurement category acc. to IEC 61010:		CAT I
type of contact:		cable lug
type of termination:		screw
rated voltage:		30 VAC / 60 VDC
rated current:		30 A
Please consider derating curve!		
contact resistance:		10 mOhm
material		
contact material:		brass
contact surface material:		nickel
housing material:		PVC-P
environmental conditions:		
temperature range:		-25 °C to +70 °C
drawing		
		

search online catalogue

Search

Messetermine

SPS/IPC/DRIVES
24. 11. 2015 - 26. 11. 2015

QR-Code

