

CATALOG LISTING

JS-557

PAGE 1 OF 1

REPLACES

PR-24110

RELEASE NO.

CHECK

7 OCT 99



SAV

CHECK

7 OCT 99


RASTER

DRAWN

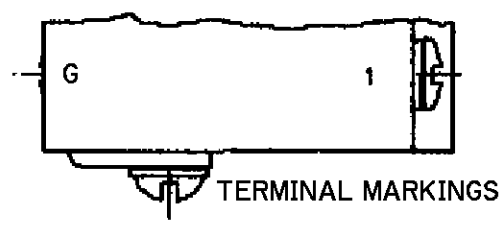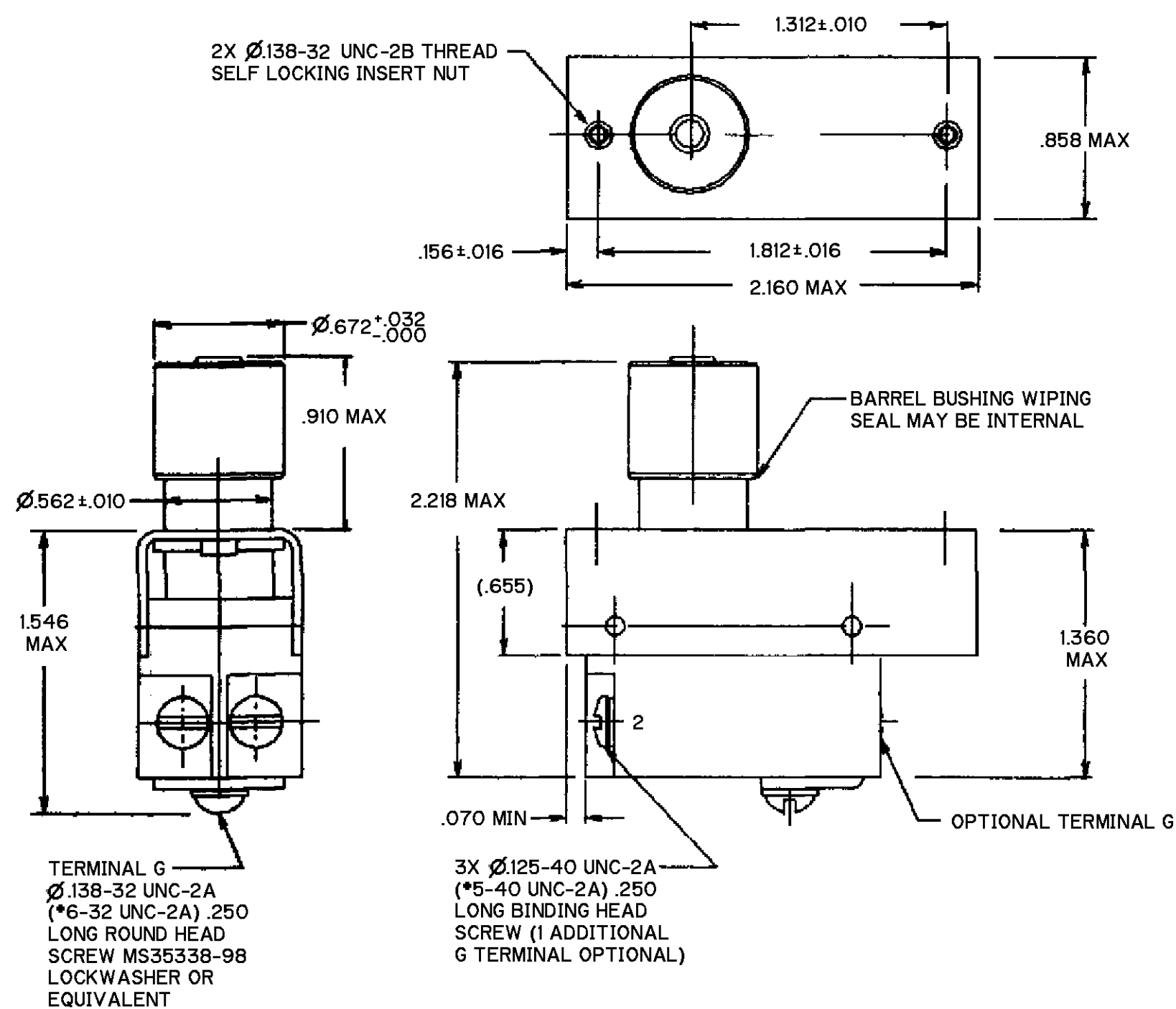

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH	
CHARACTERISTICS	ELECTRICAL DATA
ACTUATING FORCE ----- 7 - 11 LBS	CONTACT ARRANGEMENT D P S T - N O
FULL OVERTRAVEL FORCE----- 20 LBS MAX	
RELEASE FORCE----- .5 LB MIN	28 VDC
PRETRAVEL----- .090 MIN	
DIFFERENTIAL TRAVEL----- .050 MIN	INDUCTIVE
OVERTRAVEL----- .050 MIN	
TOTAL TRAVEL----- .165 MIN	
	RATED LOAD
	OVERLOAD
	.75
	1.75

THIRD ANGLE PROJECTION	
SCALE	NONE
DO NOT SCALE PRINT	
UNLESS OTHERWISE SPECIFIED TOLERANCES ARE	
ONE PLACE	(.0) ±.030
TWO PLACE	(.00) ±.015
THREE PLACE	(.000) ±.005
ANGLES	±
WEIGHT	.25 LB MAX

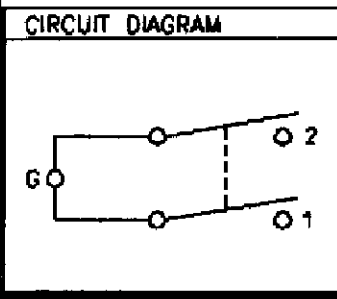

- NOTES
- 1 - SWITCH SEALED PER MIL-PRF-8805, SYMBOL 3
 - 2 - TERMINAL HARDWARE PACKET FURNISHED UNASSEMBLED:
15PA308-JS INCLUDES BUSS BRACKET AND TERMINAL SCREWS
 - 3 - MICRO SWITCH, MANUFACTURER'S CAGE CODE, CATALOG LISTING,
MILITARY PART NUMBER AND DATE CODE IDENTIFIED ON SIDE OF SWITCH
 - 4 - OPERATING TEMPERATURE RANGE: -40°C TO +85°C