

SEK CAB FLAT STD HF AWG28/7 37P 30,48m

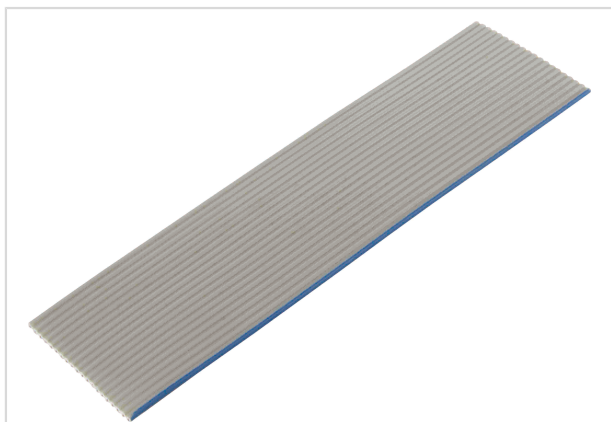


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 037 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 37P 30,48m
HARTING eCatalogue	https://b2b.harting.com/09180377001900

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (flat)

Version

Cable length	30.48 m
Number of cores	37
Core structure	AWG 28/7

Technical characteristics

Impedance	110 Ω
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance

Material properties

California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Antimony trioxide

Specifications and approvals

Specifications	UL 1581
	UL 758 Style 21151
CE	Yes

Commercial data

Packaging size	1
Net weight	2,092 g
Country of origin	USA
European customs tariff number	85444993
eCl@ss	27061801 Data and communication cable (copper)