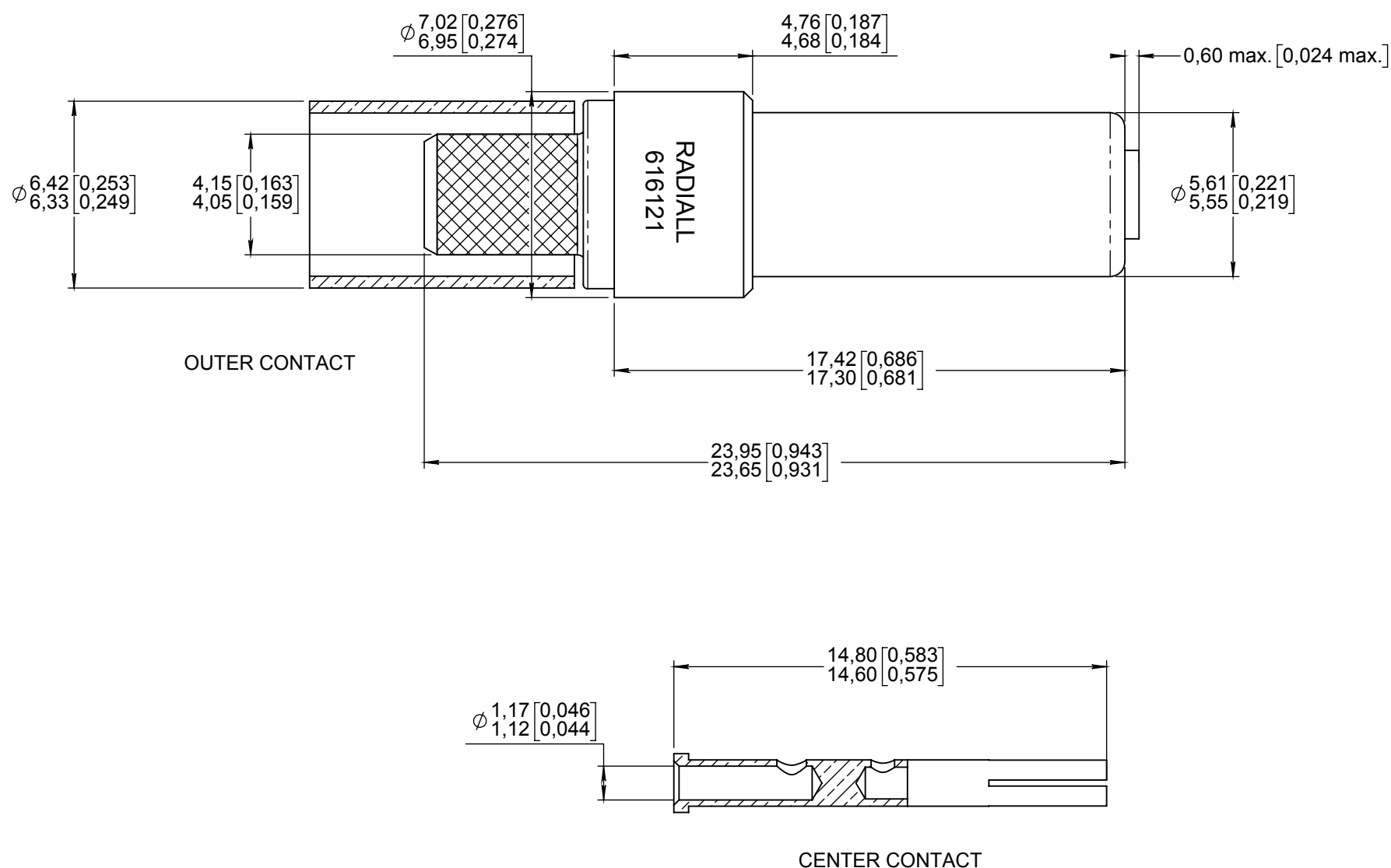


Series
DSXNONENVIRONMENTAL SIZE 5 CRIMP COAX PIN CONTACT
FOR RG142, RG223 AND KX23 CABLESIssue:
Oct. 22, 2018Page
1/1**MATERIAL :**

 
OUTER CONTACT : BRASS
INSULATOR : PTFE
CENTER CONTACT : BERYLLIUM COPPER
FERRULE : BRASS
CRIMP BARREL: BRASS

FINISH:

ALL METALIC PARTS: .00005 INCH. OF GOLD PER SAE AMS-2422 OVER NICKEL PER AMS 2403

DESIGN REQUIREMENTS :

TEMPERATURE RANGE: -65°C to +125°C
IMPEDANCE : 50 OHMS NOMINALE
DIELECTRIC WITHSTANDING VOLTAGE: 750 V rms AT SEA LEVEL
VSWR: 1.3 from DC TO 1500 MHz

WIRING INSTRUCTION PER MI CT 01 00050**DIMENSIONS : mm (inch are given for information only)**

Estimated weight : 3.45 g

CREATION

PEN: /

NOM: MOUTAULT W.

DATE: Oct. 17, 2018

APPR.: LEGENDRE T.

Oct. 22, 18	Color bands deleted (mistake)	Moutault W.	Legendre T.	
Oct. 18, 18	Add MI CT 01 00050	Moutault W.	Legendre T.	
Issue	Revisions	Name	Approved	

616121EN

RADIAL PROPRIETARY INFORMATION