


# 55A0811-20-9(C)CK0001 Product Details


 Share  Print  Email

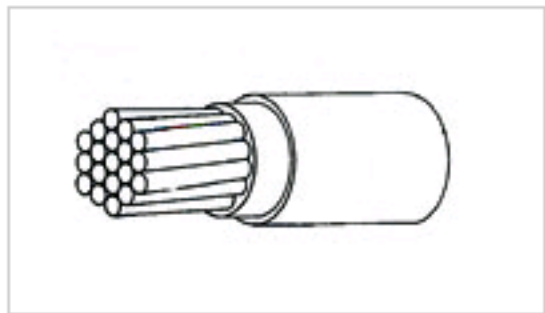

 Active

## Spec 44, Spec 55 and Spec RCW Wire and Cable

55A0811-20-9(C)CK0001

**55A0811-20-9(C)CK0001** 

TE Internal Number: D484393001

Product Highlights [View All](#)

- Cable Type = Spec 55
- Wire Source = United Kingdom
- Cable Style = Primary
- Wire Size (AWG/CM) = 20 AWG
- Voltage Rating = 600 VAC

Pricing & Availability 

Request Sample 




Add to My Part List 




Buy Product through Distributor 

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

**Please Note:**  
Use the Product Drawing for all design activity

Product Type Features	
Cable Type 	Spec 55
Cable Style 	Primary
Electrical Characteristics	
Voltage Rating (VAC)	600
Dimensions	
Conductor Outer Diameter (mm [in])	1.01 [0.040] 
Body Features	
Wire Size (AWG/CM)	20 AWG
Conductor Type	Tin-Coated Copper
Wire Color	White
Nominal Outside Diameter (mm [in])	1.47 [0.058]
Wire Diameter (mm [in])	1.47 [0.058]
Configuration Features	
Number of Conductors	1

Industry Standards	
Government/Industry Qualification	No
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
Conditions for Usage	
Temperature Range (°C)	-65 – +150 
Wire Size - Details	20 AWG 0.62 mm², 0.00095 in², 19 x 32 AWG
Operation/Application	
Application	Airframe - Normal Weight
Packaging Features	
Wire Source	United Kingdom
Other	
Brand	Raychem
Node Classification	Hook Up Wire

### Related Products

Not quite the product you're looking for?  
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)