




Part Number : [151200079](#)

Product Description : 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 8 Circuits

Series Number : 15120

Status : Active

Product Category : Flat-Flexible Cable (FFC)

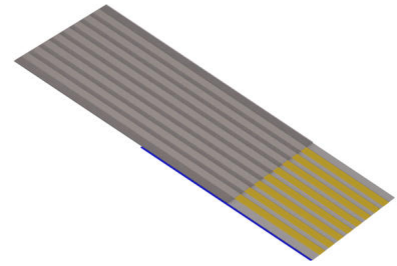

Documents and Resources

Drawings

[151200079 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[151200001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15120
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 8 Circuits
Product Name	Premo-Flex FFC Jumper
UPC	196823478024

Electrical

Current - Maximum per Contact	0.35A
Voltage - Maximum	60V AC

Physical

Cable Length	102.00mm
Circuits (Loaded)	8
Contact Layout Type	A (same side)
Design Feature	Ultra-Flexible
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +125°C

Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 8 Circuits, Gold Plating	<u>525590853</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 8 Circuits, Gold Plating	<u>527450897</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 8 Circuits, Gold Plating	<u>527460871</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 8 Circuits, Gold over Nickel Plating	<u>5034800800</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 8 Circuits, Gold over Nickel Plating	<u>5051100892</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Dual Contact Style, 1.20mm Mated Height, 8 Circuits, Gold (Au) Plating	<u>512810898</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.20mm Height, Right-Angle, Surface Mount, ZIF,	<u>545480872</u>

Bottom Contact Style, 8 Circuits, Gold (Au) Plating	
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Top Contact Style, 8 Circuits, Gold (Au) Plating	<u>545500872</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 8 Circuits	<u>781190820</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 8 Circuits	<u>781270820</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 8 Circuits, Phosphor Bronze, Gold Plating	<u>5019510830</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 8 Circuits, Gold (Au) Contact Plating	<u>512960894</u>

This document was generated on Dec 16, 2025