




All Categories 

- Products
- Markets
- Standards and Compliance
- Customer Support
- Technical Support
- Client Services
- News and Events

Home > Labels and Tapes > Labels > Product ID Labels > Barcode and Tracking Labels > Asset Tracking Labels >



 Zoom

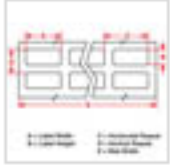

Thermal Transfer Printable Labels

Part Number: THT-37-489-10
Product Number: 67105
Material Description: Ultra Aggressive Polyester
QTY/UOM: 10,000/Roll

- Overview
- Specifications

Specifications for Thermal Transfer Printable Labels

Part Number	THT-37-489-10
Acceptable Ribbon Series	6200
Adhesive	Permanent Rubber Based
Agency Approval(s)/Compliance	UL Recognized, CSA Approved
Application	Component ID, Equipment ID, Barcoding, Asset Tracking, Rating Plates, General Purpose ID
Brady Material Number	B-489
Brand	ToughBond Series
Color	White
Description	Thermal Transfer Printable Labels
Finish	Matte
Height (in)	0.500"
Height (mm)	12.700 mm
Horizontal Repeat	1.650" (41.91 mm)
Label Type/Style	Label
Material Description	Ultra Aggressive Polyester
Material Type	Polyester
Panel Application	General Identification
Printable Area (in)	1.500" W x 0.500" H
Printable Area (mm)	38.100 mm W x 12.700 mm H
Printer Compatibility	Brady 1244, Brady 1344, Brady 2461, Brady 3481, Brady 6441, Brady 300MVP Plus, Brady 200MVP Plus, Brady 300X-Plus II, Brady 360X-Plus II, Brady 600X-Plus II, Tagus T200, Tagus T300, Thermal Transfer Printers, IP300, IP600, BBP81
Product Number	67105
Qty Per Row	2
QTY/UOM	10,000/Roll
Recommended Ribbon Series	4300
Special Properties	Ultra-aggressive adhesive, Designed for powder coated surfaces
Suggested Ribbon Part#	R4300
Surface	Smooth, Textured/Rough, Highly Textured, Low Surface Energy, Powder Coated
Surface Mount Technology (SMT)	No, this material does not work with this application
Through Hole Technology	No, this material does not work with this application
UPC Code	66282067105
Vertical Repeat	0.600" (15.24 mm)
Web Width	3.350" (85.09 mm)
Width (in)	1.500"
Width (mm)	38.100 mm
RoHS Compatibility	Pass 2011/65/EU

CONTACT US
Contact Us
Find a Distributor
Email Subscription
Brady International Sites
Brady Mobile Site

DISTRIBUTION PARTNERS
Bradyserve.com
Distributor.com
Minimum Advertised Price Policy

CORPORATE INFORMATION
About Brady
Environmental Policy
Bradycorp.com
ISO Certified
Legal

SUPPORT
Email Customer Support
Email Technical Support
Submit Website Feedback
Warranty
Sitemap