


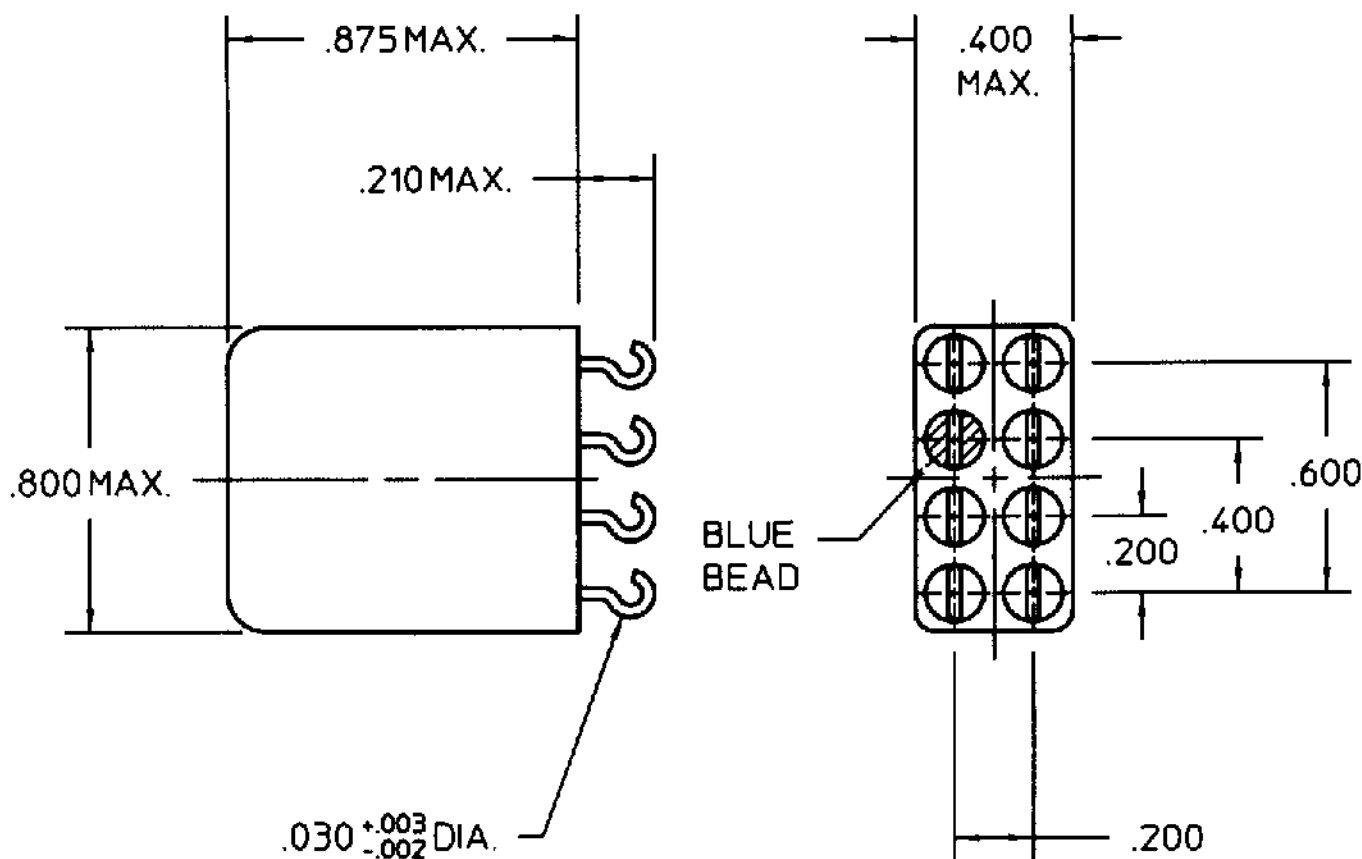

COIL: @ 25°C

RESISTANCE 9100 OHMS $\pm$ 20%

NOMINAL VOLTAGE 110 VDC

MUST OPERATE 51.0 VDC

MUST RELEASE 5.56 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

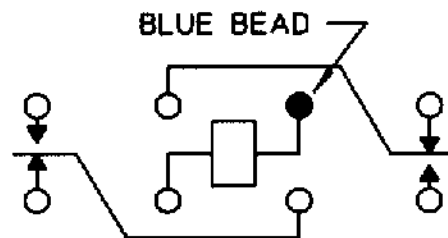

CONTACT RATING: LOW LEVEL TO
3 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. R.B. 8/29/94 CK. 8/29/94

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C.I.I. STD.

CUST. NO.

TYPE "FW" RELAY

RP7630G10