 



Type: **020816080**External dimensions: **75 x 160 x 75 mm**Weight: **540 g**

DIN rail length in mm	max. fitting length in mm	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	Allen lid screws	Silicone lid seal	Sealable lid screws
TS 15								
148	129	2	•		•	•	•	•


Maximum number of cable glands to DIN 50262*




Lid

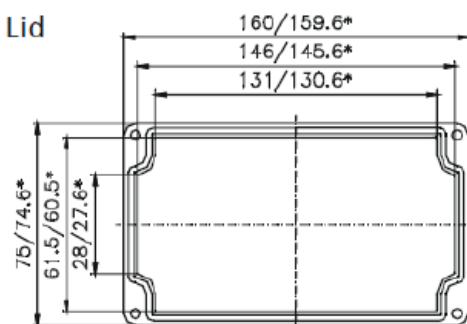

* = Conical form tapering downwards
Free dimensions-tolerance to DIN 16901 - 130

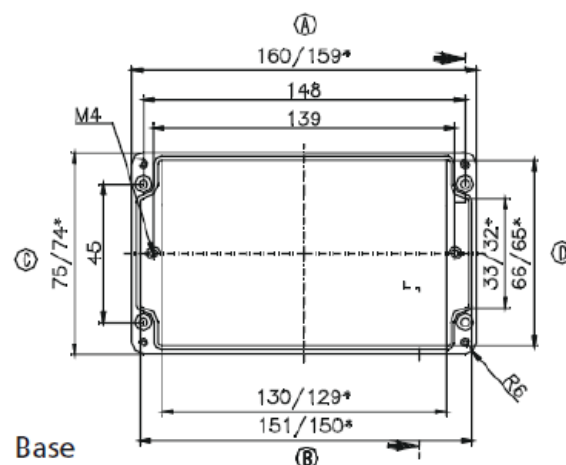

Base

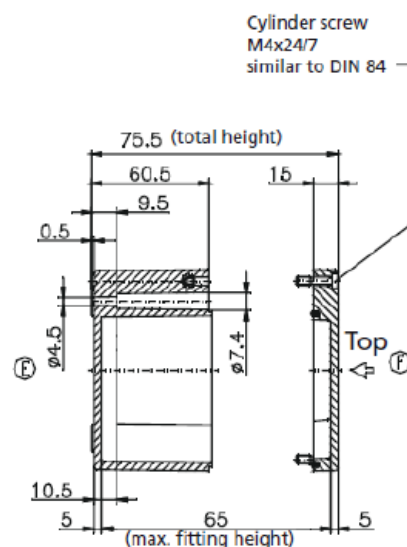

Cylinder screw
M4x24/7
similar to DIN 84

M	Corner dim.	Side		PG	Corner dim.	Side	
		A/B	C/D			A/B	C/D
12	17,25	18	5	7	17,25	18	5
16	25,30	8	2	9	21,85	11	3
20	27,60	8	2	11	25,30	8	2
25	37,95	3	1	13,5	27,60	8	2
32	48,30	2	1	16	31,05	5	1
40	60,95			21	37,95	3	1
50	69,00			29	48,30	2	
63	74,75			36	60,95		
				42	69,00		
				48	74,75		

DATE		17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	 ROSE
SHEET		1		
DESCRIPTION		ENCLOSURE, STANDARD, FIBERGLASS 75 X 160 X 75MM, RAL 7000		
SIZE	DRAWING NUMBER		020816080	REV
A				