

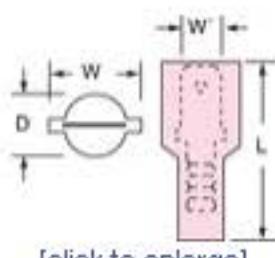
**Search This Product Catalog**[Product Catalog for Utilities & Telecommunications](#) > [Electrical Products](#) > [Wire Terminals and Connectors](#) > [3M™ Scotchlok™ Male Disconnects](#) >

By Keyword

**Go**

- ▼ Utilities & Telecommunications
  - ▼ Product Catalog for Utilities & Telecommunications
    - Electrical and Electronic Solutions for OEM
    - **Electrical Products**
    - Static Control Solutions

## 3M™ Scotchlok™ Fully Nylon Insulated Butted Seam Male Disconnect MNU18-187DMIK, 22-18 AWG

[Printer-friendly format](#)

This terminal has a wire range of 22-18 AWG and has case quantities of 1000 ea/carton.

3M Id : 80-6100-6480-2

GTIN(UPC/EAN) : 0 00 54007 02379 1

### Additional Information

**Learn More . . .**

The disconnects are attached to mating part by tongue of female part slipping over male tab. The use of dents and rolled edges on female part provides excellent holding force while allowing easy and quick disconnect.

[Packaging Data](#)

### Characteristics

<b>Agency Approvals</b>	UL and CSA
<b>Barrel Inside Diameter</b>	0.08 Inch
<b>Barrel Length</b>	0.24 Inch
<b>Barrel Style</b>	Butted
<b>Brand</b>	Scotchlok
<b>Conductor Sizes</b>	22 - 18 AWG
<b>CSA File Number</b>	LR22190
<b>Diameter (D)</b>	0.3 Inch
<b>Fastener Orientation</b>	Male
<b>Insulation Material</b>	Nylon
<b>Length (L)</b>	0.87 Inch
<b>Male Tab Width (W)</b>	0.187 Inch
<b>Maximum Insulation Outer Diameter</b>	0.145 Inch
<b>Packaging</b>	1000 per bulk box
<b>Pad Width</b>	0.187 Inch
<b>RoHS 2011/65/EU Compliant</b>	Yes
<b>Terminal Style</b>	Fully Insulated
<b>Terminal Type</b>	Disconnect
<b>Thickness</b>	0.02 Inch
<b>UL File Number</b>	E70512
<b>Width (W)</b>	0.37 Inch