


160915-5 Product Details

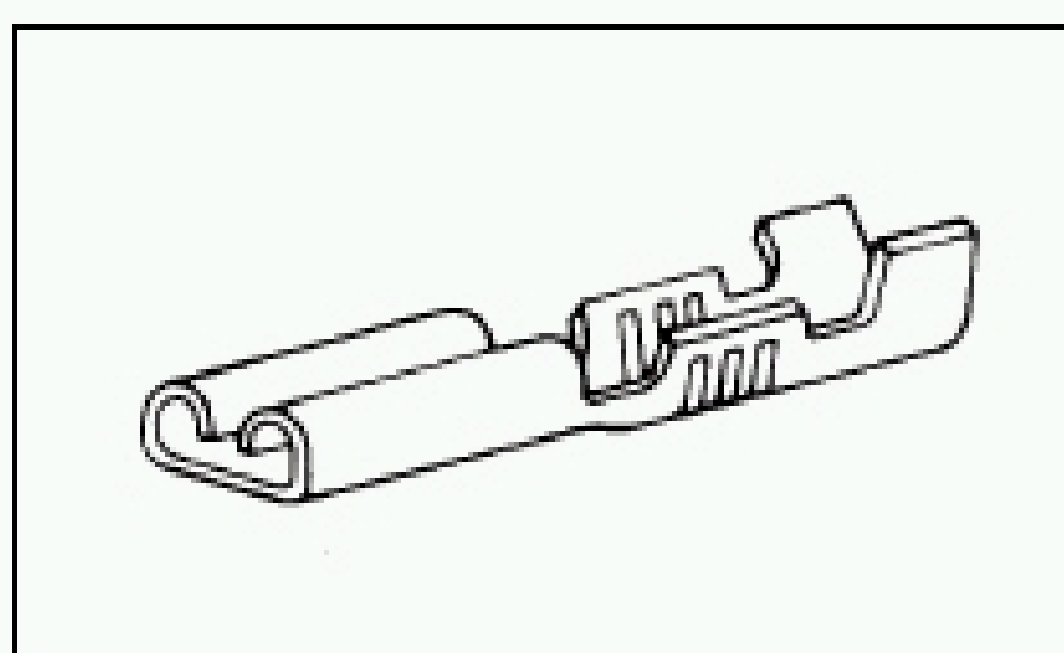

160915-5

TE Part Number: 160915-5

✓ [Active](#)

➔ [Add to Part List](#)

FASTON Uninsulated Receptacles & Housings

✓ [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Receptacle
- Tab Fit = 6.35 x 0.81 mm
- Board Mount = No
- Receptacle Style = Straight
- Insulation Support

[View all Features](#) | [Find Similar Products](#)

Live Product Chat

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Receptacle Style](#) = Straight
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Stranded
- [Insulation Diameter \(mm \[in\]\)](#) = 1.40-2.31 [.055-.091]
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = Tin
- [Crimp Type](#) = Tab-Lok

Mechanical Attachment:

- [Board Mount](#) = No

Body Related Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.50-1.00² [20-17]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Strip

Other:

- [For Hermetic Header Tab](#) = No
- [Line](#) = Premier
- Brand = AMP