




Part Number : [731000038](#)

Product Description : 50 Ohms, N Jack, Straight, Bulkhead, RG-142, RG-223, RG-400 and RG-55 Cable

Series Number : 73276

Status : Active

Product Category : RF / Coaxial Connectors

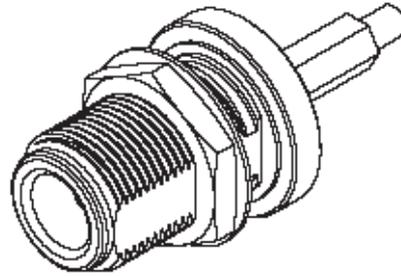

Documents & Resources

Drawings

[731000038_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73276
Description	50 Ohms, N Jack, Straight, Bulkhead, RG-142, RG-223, RG-400 and RG-55 Cable
Product Name	N
Style	Cable
Type	Medium
UPC	822348386680

Electrical

Frequency	11 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 1000 Vrms@Sea Level

Physical

Cable Attachment	Crimp
Gender	Jack
Keying to Mating Part	None
Net Weight	42.671/g
Orientation	Straight
Packaging Type	Bag
Panel Mount	Yes
Panel Mount Method	Bulkhead
PCB Mounting	N/A
PCB Thickness - Recommended	6.35mm
Reverse Polar	No
Wire/Cable Type	RG-142, RG-223, RG-400, RG-55

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

This document was generated on Feb 08, 2025