

BPDS000303168R2T00

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




MP ?

Closed Magnetic Circuit Type

Series Pdf

| Product detail        |                                               |
|-----------------------|-----------------------------------------------|
| L(mm) ±               | 3.0±0.2                                       |
| W(mm) ±               | 3.0±0.2                                       |
| T(mm) ±               | 1.55Max.                                      |
| Inductance(uH)        | 8.2                                           |
| Tolerance(±%)         | 30                                            |
| Test Frequency        | 100kHz,0.25V                                  |
| RDC(Ω)Max             | 0.281                                         |
| Isat(A)Max            | 0.8                                           |
| Irms(A)Typ            | 0.8                                           |
| Operating Temperature | −40℃~125℃ (Including self - temperature rise) |

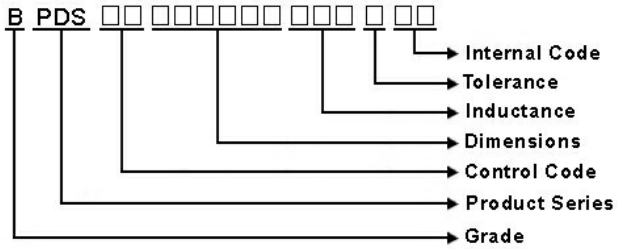

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

## Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisín](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.