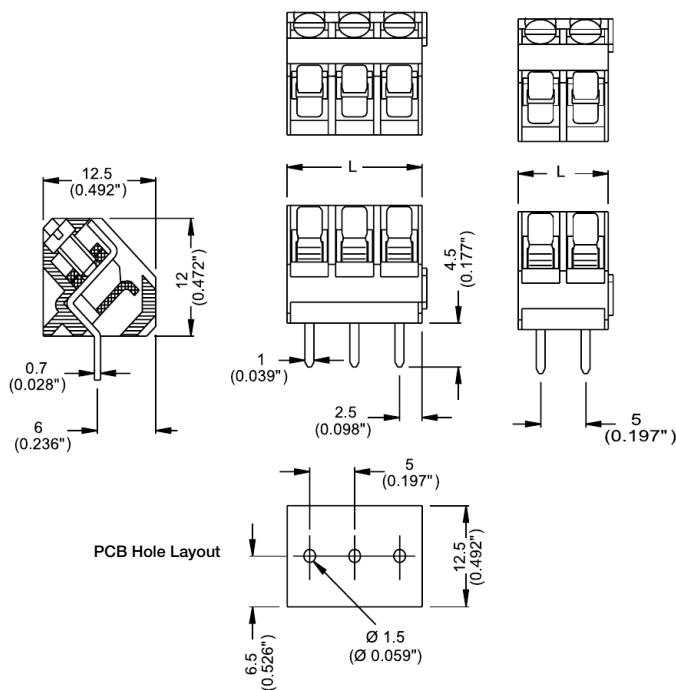


EM2205 Series**EuroMag Terminal Blocks**

45° Angle, 5.00 Centers, Modular

SPECIFICATIONS**Rating:** 10A, 300V**Center Spacing:** 0.197" (5.00mm)**Wire Range:** #12-24 AWG**Housing Material:** Grey Polyamide Type 6/6, 94V0**Contact Material:** Brass Tin-Plated**Cage Material:** Brass, Tin-Plated**Screw Size:** M2.6 Zinc-Plated Steel**Operating Temperature:** 105°C (221°F) max., -33°C (-27°F) min.**Torque Rating:** 3.5 lb-in.**Recommended PCB Hole Diameters:** 0.055" (1.40mm)**Construction:** Modular design features dovetails for interlocking to achieve longer lengths**Agency Information:**  File E62622; CE Certified

EM220505

Dimensions - mm (in)

Poles	L (mm)	Poles	L (mm)
2	10.0	14	70.0
3	15.0	15	75.0
4	20.0	16	80.0
5	25.0	17	85.0
6	30.0	18	90.0
7	35.0	19	95.0
8	40.0	20	100.0
9	45.0	21	105.0
10	50.0	22	110.0
11	55.0	23	115.0
12	60.0	24	120.0
13	65.0		

To convert to inches, divide by 25.4

Part Numbering System**Series****# of Poles**

EM2205

□□

02 to 24