
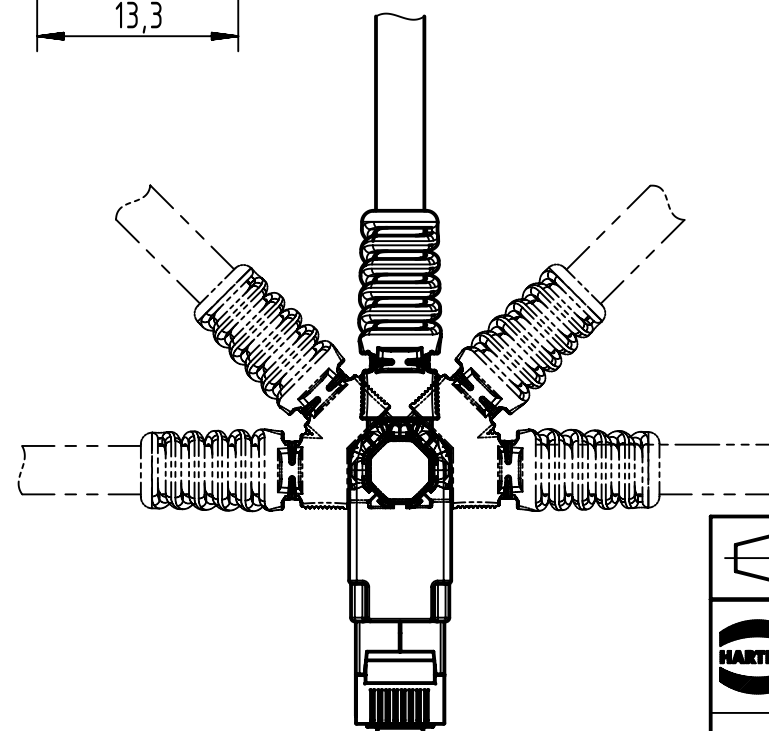
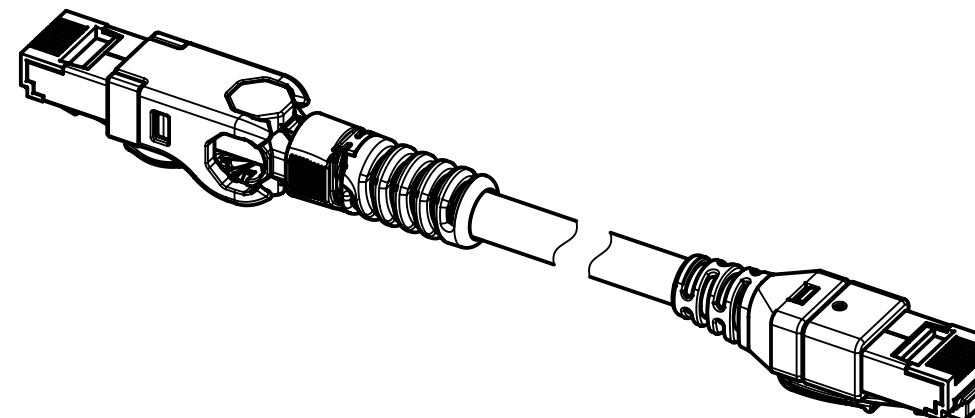
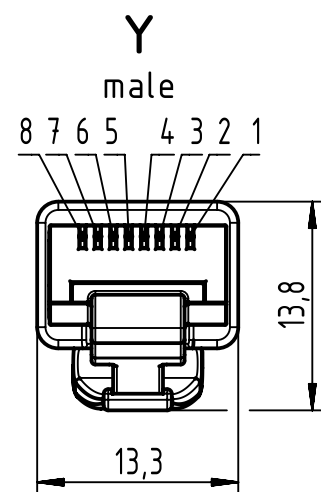
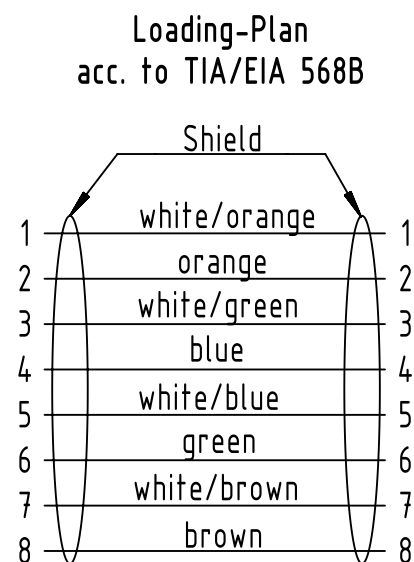
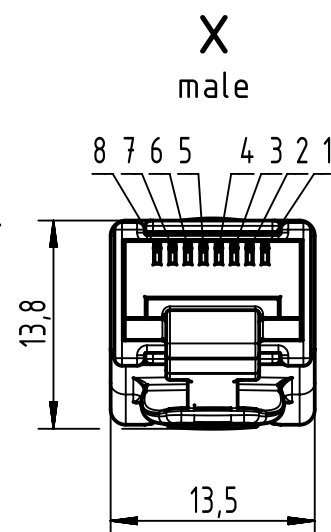


Connector Location A

Connector Location B

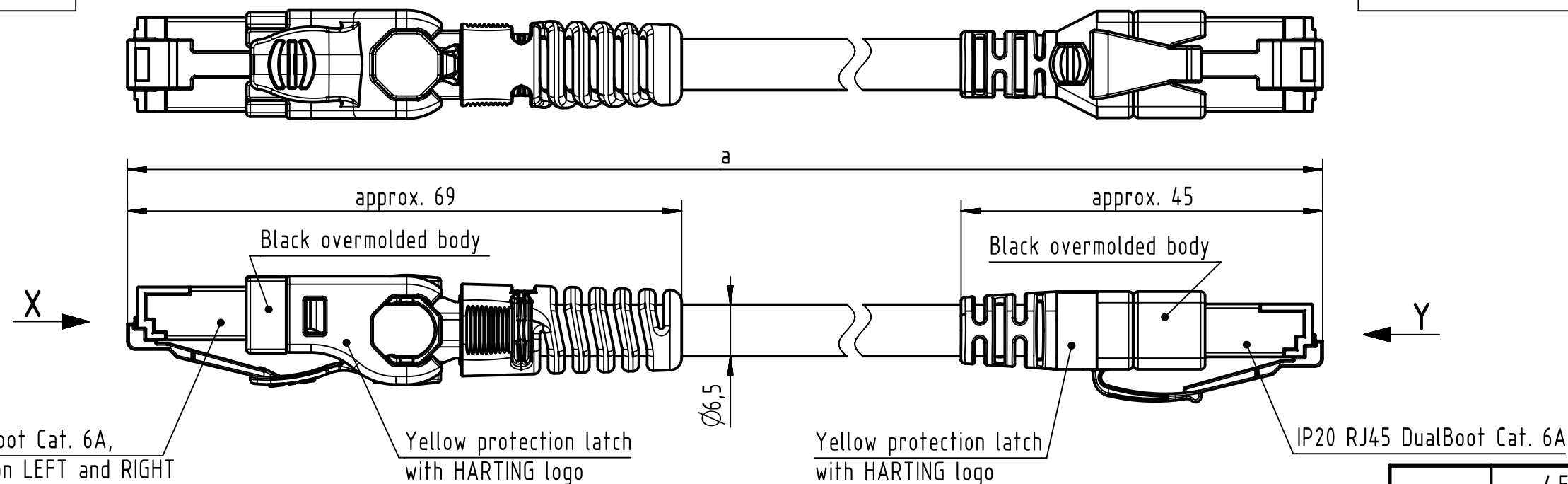

length in "1m" step	45	XXX=450
	44	XXX=440
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.5	XXX=005
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	a [m]	XXX

6.0 to 45	±1%
0.6 to 5.9	+0.04
0.2 to 0.5	+0.02
a [m]	Tolerance

4x2xAWG27/7, S/FTP, PUR, Cat. 7, yellow

09488547745XXX

Type of cable

Part no.

NOTE:

- Direction of the cable outlet can be changed up to 20x for the VarioBoot
- Mating face RJ45 acc. to IEC 60603-7 for both connectors

Temperature range:

- Fixed installation: -30°C ...+75°C
- Dynamic installation: -5°C ...+50°C

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by MUNTEANV Muntean		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean	
Department HCS - RO		Title VarioBoot RJ45 LaR - DualBoot Cat.6A		Date 2018-12-07		State Final Release	
HARTING Customised Solutions		Type TB		Number 09488547745XXX		Doc-Key / ECM-Nr. 100796625/UGD/000/B 500000144735	
D-32339 Espelkamp						Rev. B	
						Page 1/1	