

Shape


KPEG208
KPEG208H



Model Number	KPEG208	KPEG208H
Rated Frequency (Hz)	4,000 ± 500	3,500 ± 500
Operating Voltage Range (VDC)	3 ~ 20	8 ~ 18
Current Consumption (mA)	Max. 14@12VDC	Max. 13@12VDC
Sound Pressure Level (dB)	Min. 83dB@30cm / 12VDC	Min. 91dB@30cm / 12VDC
Tone	Continuous	
Operating Temperature (°C)	-20 ~ +85	-30 ~ +85
Storage Temperature (°C)	-30 ~ +95	-40 ~ +95
Weight (Gram)	1.2	
Material	ABS UL-94 1/16" HB High Heat (Black)	

Dimension

Dimension

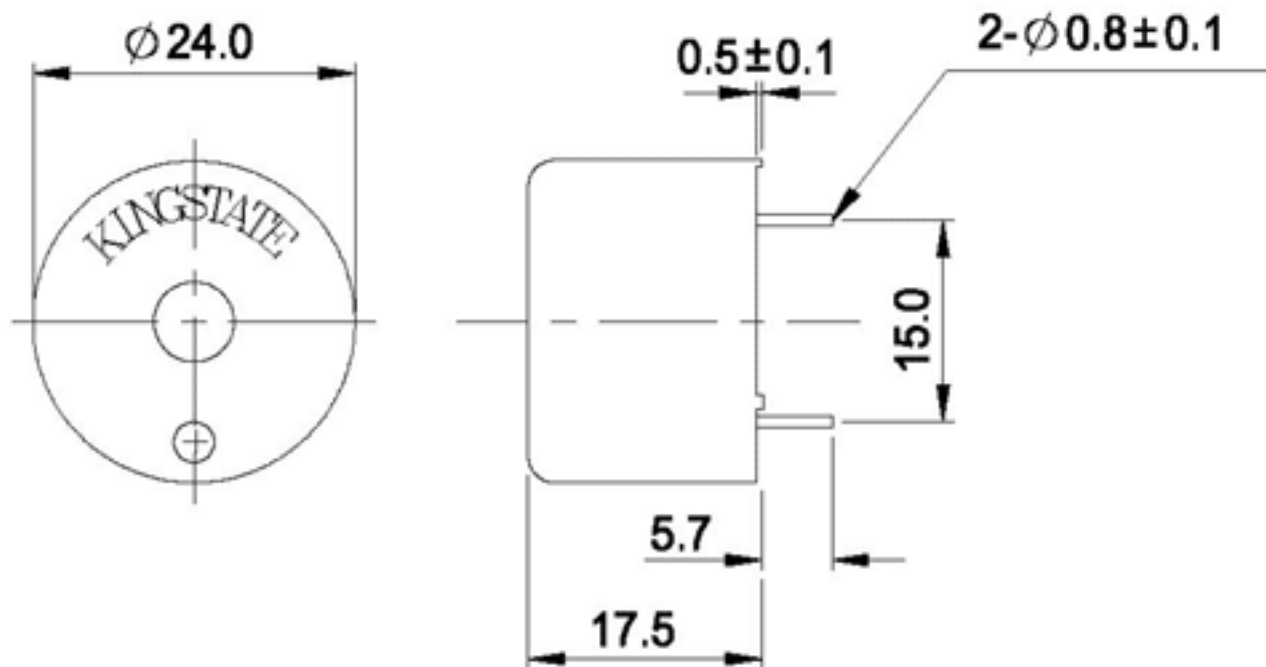


Tol : ± 0.5 Unit : mm

Characteristic

KPEG208

at 30cm

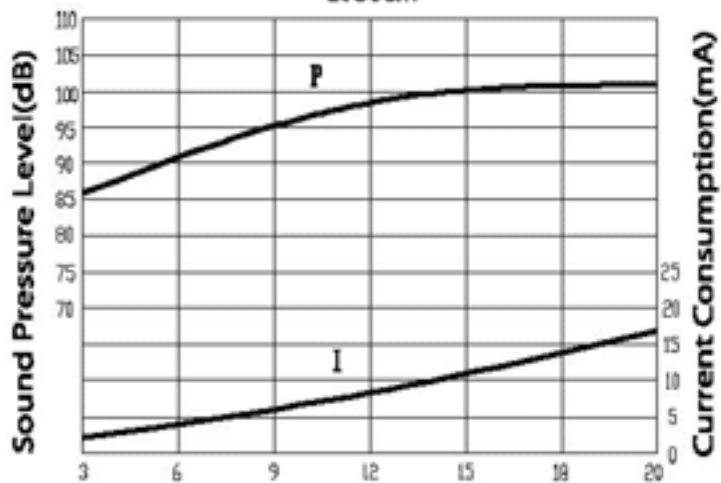

KPEG208H

at 30cm

