


[→ Honeywell.com](#) [→ Automation & Control Solutions](#)
[HOME](#)[ABOUT US](#)[KEY INDUSTRIES SERVED](#)[PRODUCTS & INFORMATION](#)[NEWS & EVENTS](#)[SALES & SUPPORT](#)[L](#)

Honeywell Sensing and Control

Search

**1TP1-6**

(Home : Products : Switches » MICRO SWITCH™ Rocker Switches » Power-duty Rocker Switches » TP)

narrow your search

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1701)
- Sensors (6224)
- Switches (9749)
- Wireless (39)

Technology

- Control and Instrumentation (1052)
- Electromechanical (9301)
- Magnetic (541)
- Optical/Infrared (1042)
- Thick Film (1764)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



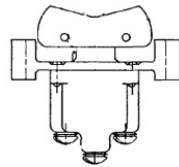
Wireless Web Site
WGLA and WPM
XYR6000™

[find out more](#)

white papers

Wireless Switches Offer Unlimited Benefit
Basic Switches Are Not Created Equal
Applying Precision Switches
Sensors for Medical Devices
New Ways to Measure Torque
Choosing Safety Switches
Specifying Hour Meters

Need help?

[Click here to contact us](#)

TP Series Rocker Switch, 1 pole, 2 position, Screw terminal, Flush Panel Mounting

Actual product appearance may vary.

[Sales & Service](#)[Distributor Inventory](#)
[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Product Type	MICRO SWITCH™ Rocker
Contact Type	Silver Cadmium Oxide Contacts
Circuitry	SPST
Action	2 position
Circuitry/Operating action	<div> <div> Keyway Momentary Position </div> <div> </div> </div> <div> <div> Opposite Keyway Position </div> <div> </div> </div>
Mounting	Flush Panel
Lamp Type	Translucent
Termination	Screw
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc; 0.5 A at 250 Vdc; 0.5 A to 15 A at 0.5 Vdc to 28 Vdc; 0.5 A to 10 A at 0.5 Vac to 7 Vac
LED/Lamp/Neon Voltage	L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"
Comment	Silver cadmium oxide contacts
Availability	Global
UNSPSC Code	302119
UNSPSC Commodity	302119 Switches and controls and relays
Series Name	TP

contacts

Customer Service
Technical Support
Global Sales & Service
View Site Demo
Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.

Meet Dr. Larry



my links

Login to iCOM
Login to Rep/AD Portal
Login to Digital University

News Center

HONEYWELL ANNOUNCES ADDITION TO RELIALIGN™ RESIDENTIAL DOOR INTERLOCK SWITCHES THAT FEATURE RUGGED, PLASTIC HOUSING

HONEYWELL RELEASES UNLIMITED POTENTIAL WITH NEW LIMITLESS™ WIRELESS SWITCHES

HONEYWELL'S XYR6000 WIRELESS POSITION SENSOR ENABLES MONITORING IN HAZARDOUS AREAS AND REMOTE LOCATIONS

MICRO SWITCH
Anniversary site

[Terms & Conditions](#) | [Privacy Statement](#) | [Site Map](#)