


Part Number : [5033004110](#)

Product Description : Easy-On Front Flip FPC Connector, 0.25mm Pitch, Surface Mount, 1.20mm Height, Top Contact, Right-Angle, Low Halogen, 41 Circuits, 3000 Pieces per Reel

Series Number : 503300

Status : Active

Product Category : FFC / FPC Connectors

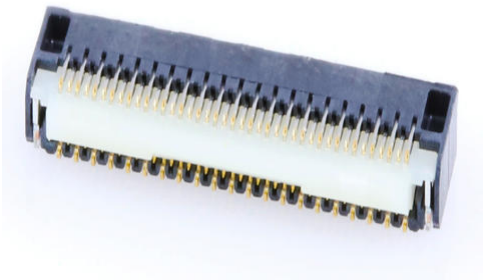

Documents and Resources

Drawings

[5033004110 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

[5033004110.dxf](#)


Specifications

[SPK-503300-001-001.pdf](#)

[PS-503300-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)6375-DC (05 Nov 2025) SCIP:16713a46-6685-4668-b435-a828d2027c63

EU RoHS	Compliant per EU 2015/863
---------	---------------------------

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	503300
Description	Easy-On Front Flip FPC Connector, 0.25mm Pitch, Surface Mount, 1.20mm Height, Top Contact, Right-Angle, Low Halogen, 41 Circuits, 3000 Pieces per Reel
Comments	Beige actuator
Product Name	Easy-On
UPC	883906199302

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V

Physical

Actuator Type	Front Flip
---------------	------------

Circuits (Loaded)	41
Color - Resin	Black
Contact Position	Top
Durability (mating cycles max)	10
Mated Height	1.20mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	82.451/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Mounting	Surface Mount
PCB Retention	None
Pitch - Mating Interface	0.25mm
Plating min - Mating	0.102µm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FPC only

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.25mm Pitch Premo-Flex FPC Jumpers	<u>15014</u>

This document was generated on Dec 18, 2025