



Connector Location A

Connector Location B

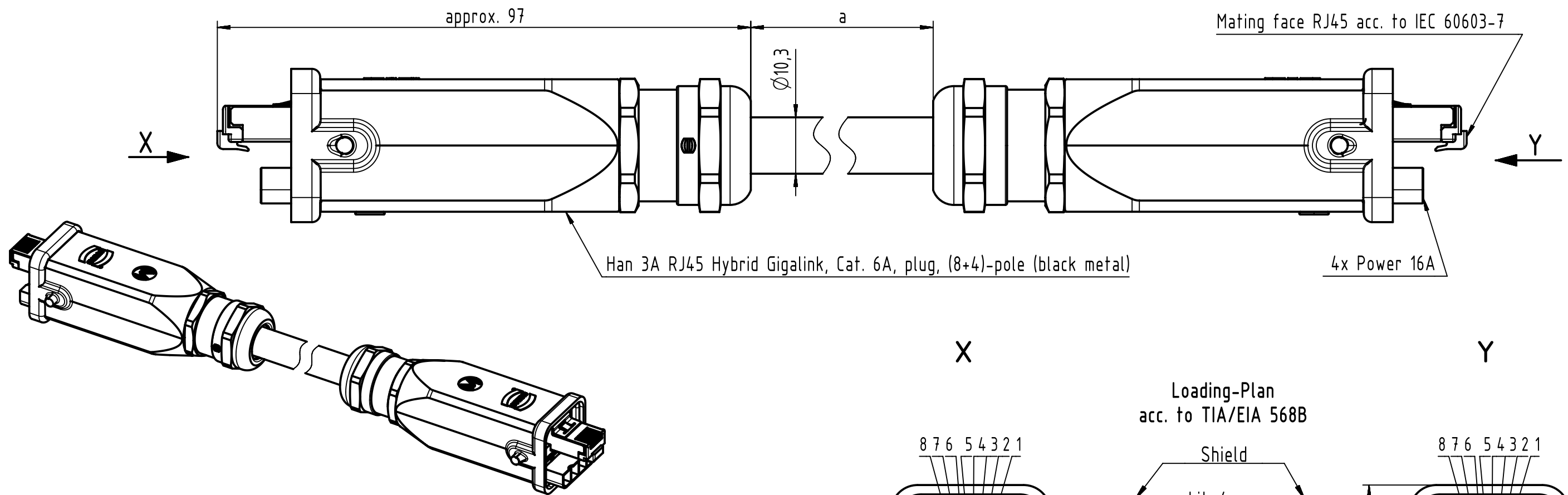


22	09457251548	Hybrid cable 4x2xAWG26/7+4x1.5mm ² , PUR, Cat.6, black	60
21	09457251547		50
20	09457251546		40
19	09457251545		30
18	09457251552		25
17	09457251544		20
16	09457251543		15
15	09457251550		13
14	09457251549		12
13	09457251542		10
12	09457251541		9
11	09457251540		8
10	09457251539		7
9	09457251538		6
8	09457251537		5
7	09457251536		4
6	09457251535		3
5	09457251551		2.5
4	09457251534		2
3	09457251533		1.5
2	09457251532		1
1	09457251531		0.5
Cont. no.	Part no.	Type of cable	Dim. a[m]

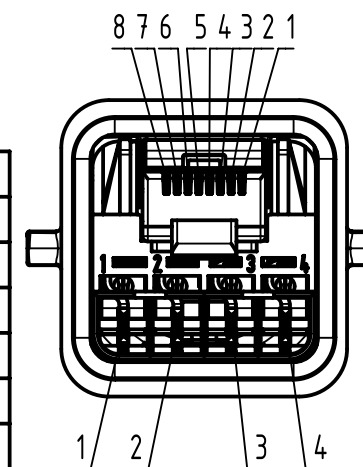

Loading-Plan
acc. to TIA/EIA 568B

Shield

Pin	Color	Pin	Color
1	white/orange	16	white/green
2	orange	17	blue
3	white/green	18	white/blue
4	blue	19	green
5	white/blue	20	white/brown
6	green	21	brown
7	white/brown	22	black 1
8	brown	23	black 2
9	black 1	24	black 3
10	black 2	25	black 4
11	black 3		
12	black 4		
13	black 5		
14	black 6		
15	black 7		

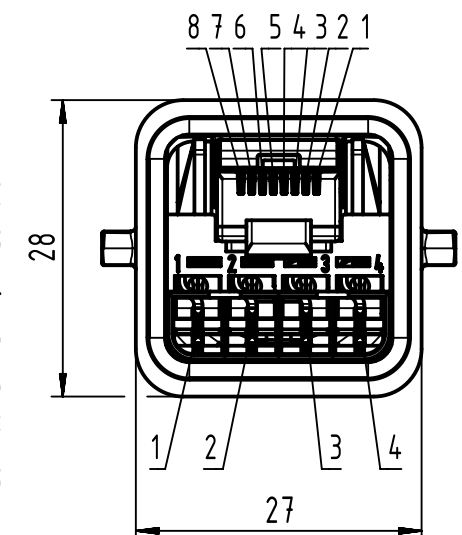

Protection level: IP67/65
Temperature range: -20°C ... +80°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing					
		All rights reserved Department HCS - RO		Created by STOCHECIC Stocheci		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean		Date 2018-06-20		State Final Release	
HARTING Customised Solutions D-32339 Espelkamp		Title Han3A RJ45 Hybrid Cable Assembly							Doc-Key / ECM-Nr. 100178367/UGD/003/G 500000136574				
		Type TB		Number 09457251XXX					Rev. G		Page 1/1		