

	SPECIFICATION FOR PIEZO BUZZER		
	TOTAL PAGE	06	www.be-star.com RoHS

Customer		Model Name	BPT3226C12VDCB
Customer P/N		Product No.	033854
Date	2014 Nov. 25	Issue No.	BS/TEA01.987A
Page	01 of 06	Issue Date	2014/07/25

Approval:

- 1.Characteristics
- 2.Test Method
- 3.Drawing
- 4.Reliability Test
- 5.Packing
- 6.History change record

Drawn by	Checked by	Approved by	Customer approved

BESTAR HOLDING CO.,LTD

No.199 HuangHe West Road,New district,ChangZhou,JiangSu Province,P.R.China

Tel: +86 519 88222567 **Fax:** +86 519 88222551

E-mail: wu@be-star.com **http://www.bestargroups.com**

BPT3226C12VDCB




1. Characteristics

Electrical and Mechanical Characteristics

No.	Item	Specifications
1.	Operating Voltage	5-28VDC
2.	Rated Voltage	12VDC
3.	Current Consumption	3-18mA
4.	Sound Pressure Level at 1m	85±3dB
5.	Resonant Frequency	3000±500Hz
6.	Tone Pin1(+) & Pin3(-C)	Constant
7.	Operating Temperature	-20...+65°C
8.	Storage Temperature	-30...+75°C
9.	Colour	Black
10.	Weight	25g±20%

*On-Off tone:100+/-20C/M

2. Test Method

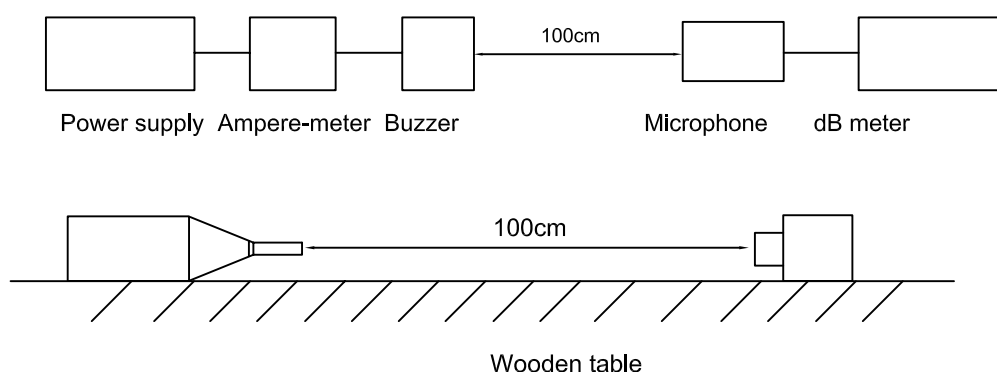


				Date:	2014/07/25	BPT3226C12VDCB
				Drawn by:	朱卫华	
A	2014/07/25	朱卫华		Checked by:	陈小东	Piezo Buzzer
Rev.	Date	Drawn	Note	Approved by:	程久生	
BESTAR HOLDING CO.,LTD						DRG NO:BS/TEA01.987A
www.bestargroups.com wu@be-star.com						Page:02 of 06

BPT3226C12VDCB

3.Drawing

Unit:mm Tolerance:±0.3mm

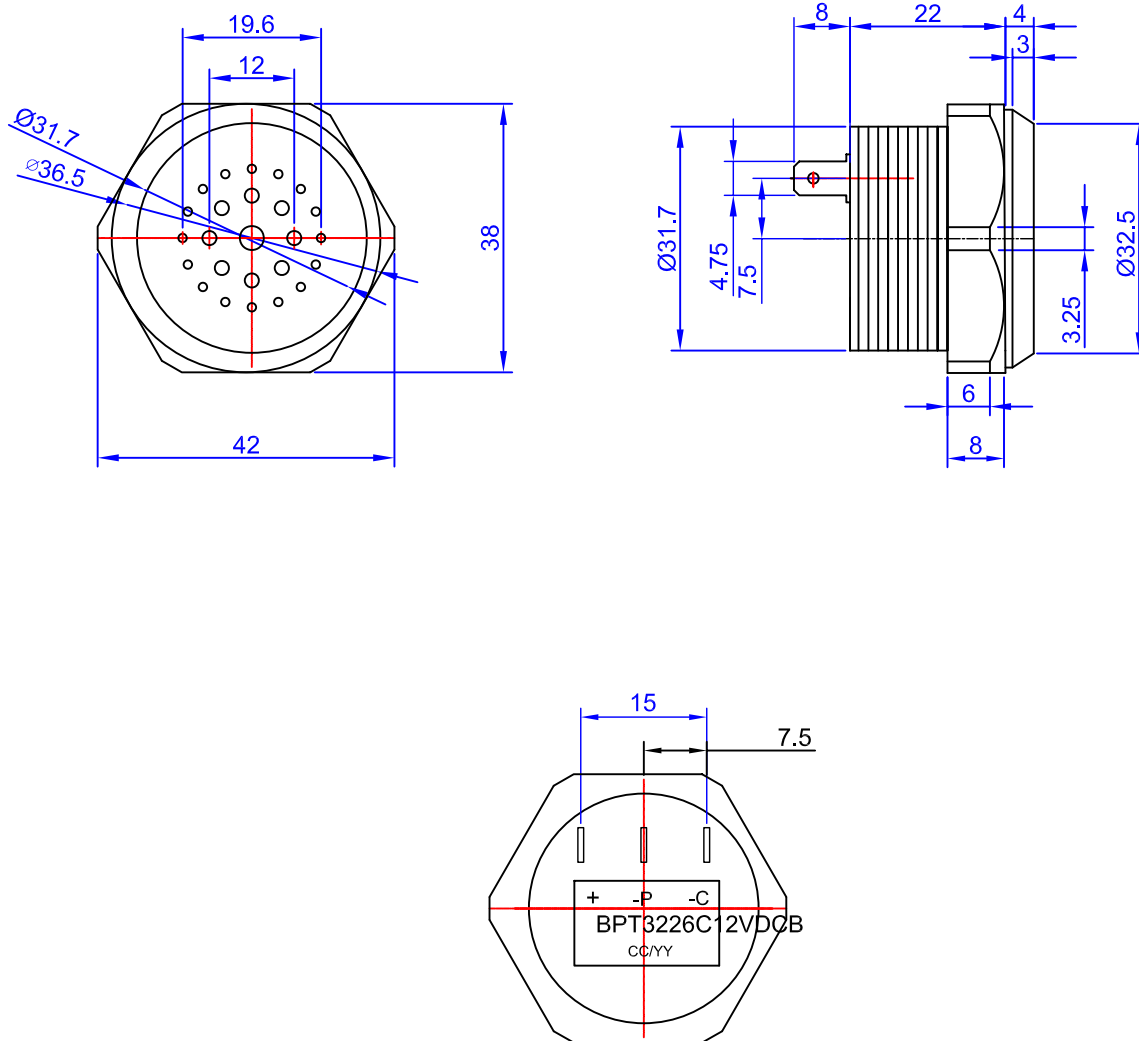

*CC/YY:周期/年份

				Date:	2014/07/25	BPT3226C12VDCB
				Drawn by:	朱卫华	
A	2014/07/25	朱卫华		Checked by:	陈小东	Piezo Buzzer
Rev.	Date	Drawn	Note	Approved by:	程久生	
BESTAR HOLDING CO.,LTD						DRG NO:BS/TEA01.987A
www.bestargroups.com wu@be-star.com						Page:03 of 06

BPT3226C12VDCB

4. Reliability test

4.1 high temperature test

Temperature +75°C
Duration 96hrs

4.2 low temperature test


Temperature -20°C
Duration 96hrs

4.3 life test in normal temperature

Power supply 12V
Duration 500hrs


4.4 temperature cycle test

 Cycles 5



4.5 Humidity cycle test

 Cycles 5



all these tests above should be measured after leaving normal temperature for 2hrs.

4.6 Drop test

Height 70cm

(to 10mm thickness woodenboard)

Direction 3

Notice: All specification must be satisfied in this condition.


				Date:	2014/07/25	BPT3226C12VDCB
				Drawn by:	朱卫华	
A	2014/07/25	朱卫华		Checked by:	陈小东	Piezo Buzzer
Rev.	Date	Drawn	Note	Approved by:	程久生	
BESTAR HOLDING CO.,LTD						DRG NO:BS/TEA01.987A
www.bestargroups.com wu@be-star.com						Page:04 of 06

BPT3226C12VDCB



5.Packing

Packing Quantity :20pcs per box
660pcs per carton
carton size 56x23x50cm,

Grid

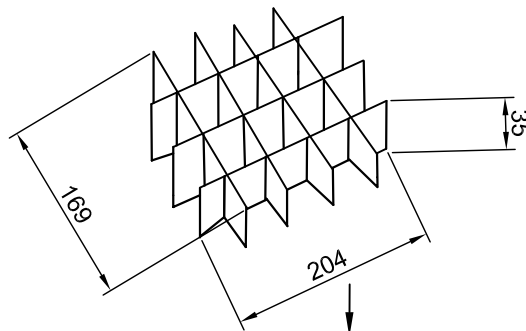

small carton

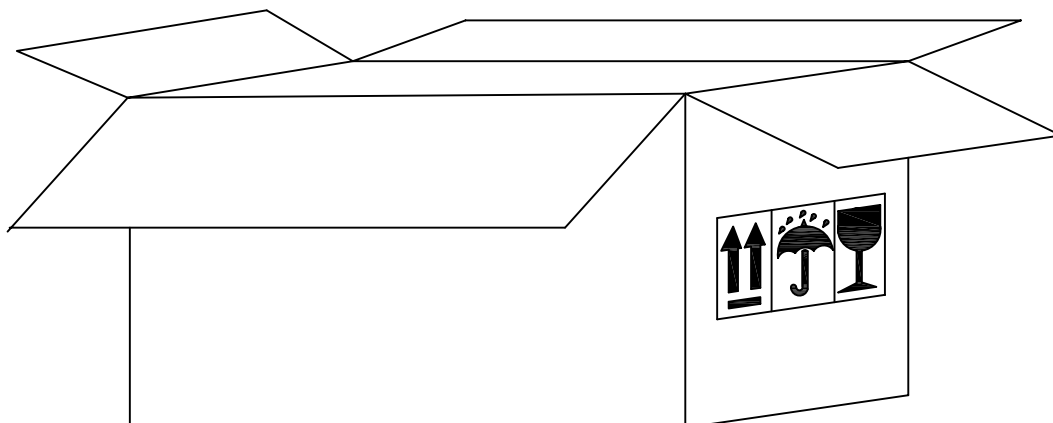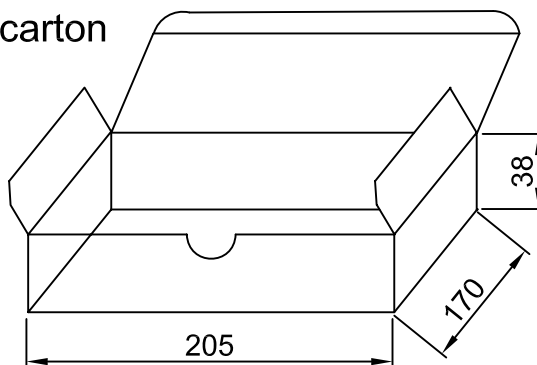

This print and information there in are propriety to BeStar Holding Co., Ltd. and shall not be used in whole or in part without its written content

A				Date:	2014/07/25	BPT3226C12VDCB
				Drawn by:	朱卫华	
	A	2014/07/25	朱卫华	Checked by:	陈小东	Piezo Buzzer
	Rev.	Date	Drawn	Note	Approved by: 程久生	
BESTAR HOLDING CO.,LTD						DRG NO:BS/TEA01.987A
www.bestargroups.com wu@be-star.com						Page:05 of 06

6. History Change Record

[illegible]

				Date:	2014/07/25	BPT3226C12VDCB	
				Drawn by:	朱卫华		
A	2014/07/25	朱卫华		Checked by:	陈小东	Piezo Buzzer	
Rev.	Date	Drawn	Note	Approved by:	程久生		
BESTAR HOLDING CO.,LTD www.bestargroups.com wu@be-star.com						DRG NO:BS/TEA01.987A	Page:06 of 06