



121-001

Type B Series 72 Annular Convulsed Tubing

Thermally Stabilized Kynar®

TYPE B INTERNAL TIN/COPPER BRAID

121-001-16

Product Series ————

Dash No. (Table I) ————

Basic No. ————

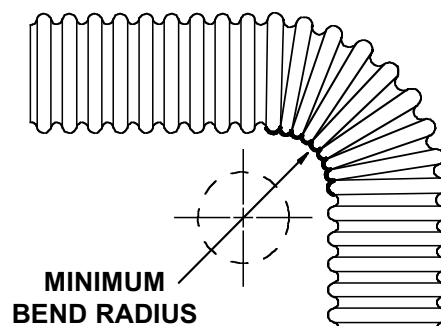
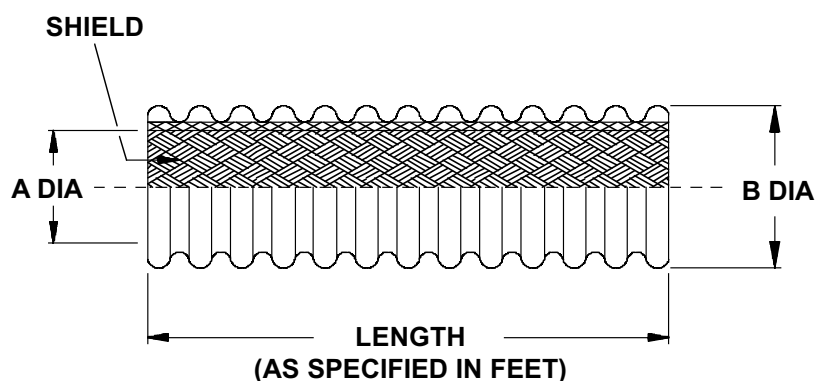


TABLE I					
DASH NO.	A DIA		B DIA		MINIMUM BEND RADIUS
	MIN	MAX	MIN	MAX	
09	.17 (4.3)	.21 (5.3)	.38 (9.7)	.42 (10.7)	.75 (19.1)
12	.26 (6.6)	.30 (7.6)	.48 (12.2)	.52 (13.2)	1.00 (25.4)
16	.38 (9.6)	.43 (10.9)	.60 (15.2)	.66 (16.8)	1.38 (35.1)
20	.50 (12.7)	.55 (14.0)	.71 (18.0)	.77 (20.0)	1.69 (42.9)
24	.62 (15.7)	.68 (17.3)	.88 (22.4)	.94 (23.9)	1.88 (47.8)
28	.74 (18.8)	.80 (20.3)	1.00 (25.4)	1.08 (27.4)	2.00 (50.8)
32	.86 (21.8)	.93 (23.6)	1.12 (28.4)	1.20 (30.5)	2.38 (60.5)
40	1.11 (28.2)	1.18 (30.0)	1.36 (34.5)	1.44 (36.6)	2.88 (73.2)

Metric dimensions (mm) are in parentheses.

Note: Tubing supplied in random lengths.
For specific size lengths, consult factory.