



SCHEMATIC

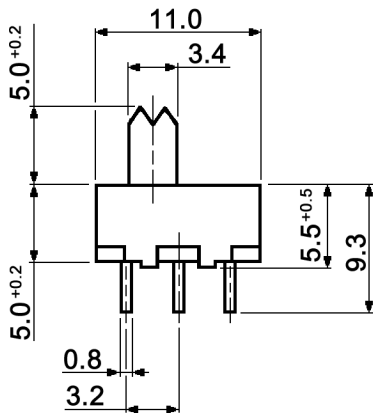

Specifications:

Contact rating:	350mA, 30V DC
Contact resistance:	20mOhm max.
Insulation resistance:	100MOhm min. at 500V DC
Dielectric strength:	500V, 50Hz for the duration of 1 minute
Operating temperature:	-20°C to +85°C
Mechanical life:	min. 10 000 cycles
Soldering conditions:	auto-soldering: max.: 260 +/-5°C, 3sec.
Contact timing:	non-shorting
Slide colour:	black
Material:	Contacts: copper alloy, silver plated over nickel barrier

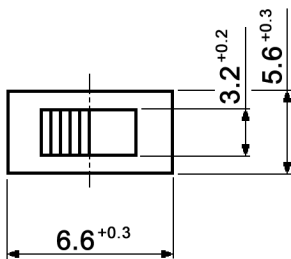

Tolerances:			Date	Name	MFP 120		
			11/08	dr			
					knitter-switch		
					20 13 55		Page
							1/1
Modifications	Date	Name					