

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1210641756

Status:

Active

Overview:

mPm DIN Valve Connectors

Description:

mPm DIN Valve Connector, Form A-18mm, PG7 Internal Threads, 2 Pole Plus Ground Terminal, 250V AC/300V DC, Red LED, Transparent, Nitrile Gasket

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E218123

General

Product Family

Field Attachable / Accessories

Series

121064

Form

A - 18mm

IP Rating

IP65, IP67

Material - Contact

Brass

Overview

mPm DIN Valve Connectors

Product Name

mPm

Type

Field Attachable Connector

UPC

884982302198

Physical

Cable Diameter

N/A

Coupling Type

Internal Thread

Diagnostics / LEDs

Yes

Diagnostics Port

No

Gender

N/A

Keyway

None

Material - Connector Body

Polypropylene

Material - Coupling Nut

N/A

Material - Plating Mating

Silver

Net Weight

21.762/g

Orientation

90° Angle

Pitch - Mating Interface

18.00mm

Poles

2

Temperature Range - Operating

-40°C to +90°C

Wire Size AWG

N/A

Electrical

Current - Maximum per Contact

16.0A


Voltage - Maximum

250V AC / 300V DC

Material Info

Engineering Number

S182M6TC321

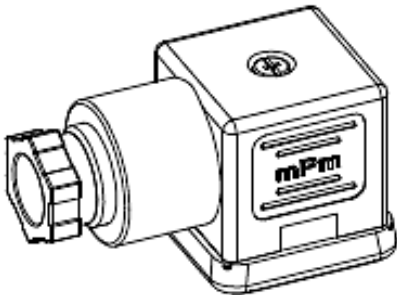

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

121064 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION