 




# CONNECTOR HOUSINGS



✓ Active

TE CONNECTIVITY (TE)

## POWER DBL LOCK PLUG HSG 3P(GWT)

Power-Signal Double Lock | Power Double Lock

5-177899-1

TE Internal Number: 5-177899-1

Always EU RoHS/ELV Compliant


Connector System **Wire-to-Board, Wire-to-Panel, Wire-to-Wire**

Centerline **3.96 mm [ .156 in ]**

Number of Positions **3**

Number of Rows **1**

Housing Material **Nylon 6/6**

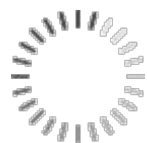

No documentation available.

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features	Connector System	<b>Wire-to-Board, Wire-to-Panel, Wire-to-Wire</b>
	Connector Style	<b>Plug</b>
	Sealed	<b>No</b>
	Applies To	<b>Panel, Printed Circuit Board, Wire/Cable</b>
	Product Type	<b>Connector</b>
	Connector Type	<b>Housing</b>

Configuration Features	Number of Positions	<b>3</b>
	Number of Rows	<b>1</b>

	Selectively Loaded	<b>No</b>
	Preloaded	<b>No</b>
Electrical Characteristics	Operating Voltage (VAC)	<b>300</b>
Body Features	Sealable	<b>No</b>
Contact Features	Contact Type	<b>Socket</b>
	Shunts/Shorting Bars	<b>Without</b>
	Multiple Contact Types	<b>Without</b>
Mechanical Attachment	Contact Retention	<b>Without</b>
Housing Features	Centerline	<b>3.96 mm [ .156 in ]</b>
	Housing Material	<b>Nylon 6/6</b>
	Housing Color	<b>Natural</b>
Dimensions	Length (mm)	<b>13.9</b>
	Height	<b>20.6 mm [ .811 in ]</b>
	Width (mm)	<b>6.9</b>
Usage Conditions	Operating Temperature Range	<b>-30 – 105 °C [ -22 – 221 °F ]</b>
Operation/Application	Assembly Integration Feature	<b>Without</b>
	For Use With	<b>Cap: 177907 or 179464, Contacts: 177914 or 177915, Double Lock Plate 177919-1, Header: 179839, Header: 179844 (3 pos./ 2 circuit)</b>
Identification Marking	Circuit Identification Feature	<b>Without</b>
Industry Standards	CSA Rating	<b>Certified</b>
	CSA File Number	<b>LR7189</b>
	UL Rating	<b>Recognized</b>
	CSA Certified	<b>Yes</b>
	VDE Tested	<b>Yes</b>
	UL File Number	<b>E28476</b>

Agency/Standard

CSA, UL

---

Packaging Features

Packaging Quantity

400

Packaging Method

Bag

---

Other

Comment

**Part 179844 is a 3 position header, no pin in position 2.**

---

Product Compliance

[Statement of Compliance](#)

PDF

[VIEW ALL PRODUCT COMPLIANCE](#)

