



Part Number:	SM500416-1	DRAWN	5/23/2018
		CJ	
Description:	Dynamic Speaker	CHECKED	5/30/2018
		C.H.	
		APPROVED	5/30/2018
		C.E.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com			


Top View

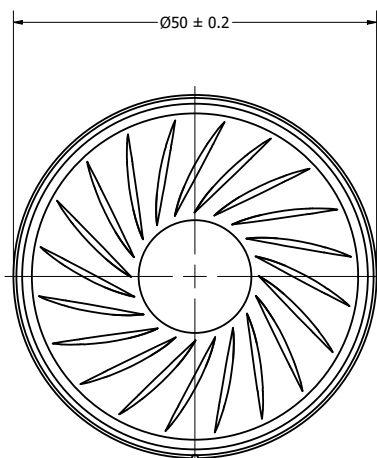

Side View

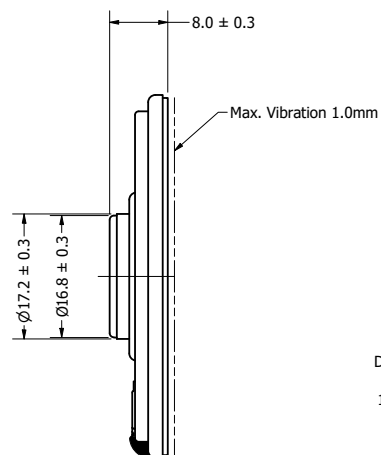

Bottom View

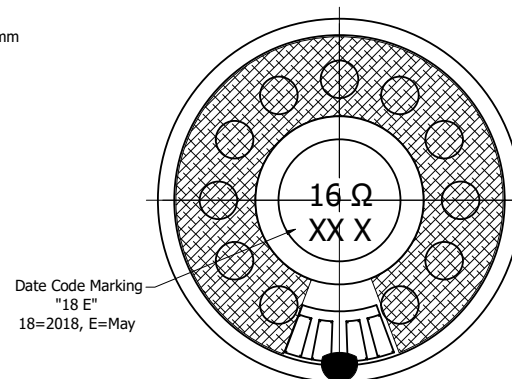

Items	Specifications	Conditions	REVISION HISTORY			
Sound Pressure Level	97	dB (@ 10cm), Avg.	REV	DESCRIPTION	DATE	APPROVED
Resonant Frequency	400	Hz		Released from Engineering	5/30/2018	C.E.
Frequency Range	400 ~ 5,000	Hz		Update back magnet detail	2/3/2018	C.E.
Nominal Power	0.25	W	1			
Max. Power	0.5	W				
Impedance	16	Ω		NOTES		
Cone Material	Mylar			1) All dimensions are in mm unless otherwise noted		
Mount Type	Flush Mount			2) All tolerances are ± 0.5 mm unless otherwise noted		
Storage Temperature	-30 ~ +70	°C		3) All parts meet RoHS		
Operating Temperature	-20 ~ +60	°C		4) Subject to change or redrawn without notice		