



Basler

Technical Specification

Patchcable GigE, CAT.6, S/FTP, 2 x RJ45

5m, 10m, 20m, 30m

for Basler GigE Series

Order Numbers:

5m: 2000030284

10m: 2000030285

20m: 2000030286


30m: 2000030287

Basler AG



An der Strusbek 60-62

22926 Ahrensburg, Germany

Technical Specification:

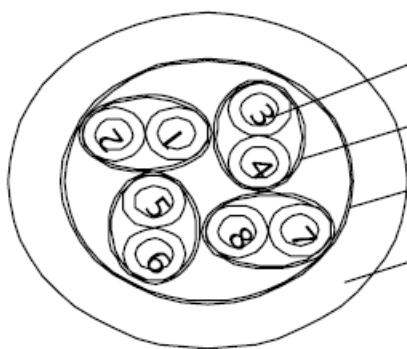(Product name)			CAT.6 S/FTP	
(items) (AWG			(unit)	(The specification value)
size) (core			Awg	#27
number)			Pcs	4P
c r o s s e d w i r e	(conductor)	(material)		tinned copper wire
		(filling)		
		(structure)	No.mm	stranded 7*0.13
		(crossed O.D)	mm	0,4
	(insulate)	(material)		HDPE
		(thickness)	mm	0,335
		(O.D)	mm	1,05
		(color)	white-blue white-yellow pink-green white-brown	
	(tapes)	(material)		AL flake
		(structure)		
		(overlap rate)	%	25
(earthing wire)		(material)		
		(structure)	No.mm	
(braid)		(material)		tinned copper wire 16*5*0.1
		(shield rate)	%	65
(jacket)		(material)		PVC<LSOH>
		(minimum thickness)	mm	0,55
		(standard thickness)	mm	0,6
		(O.D)	mm	6,2
		(color)		
(print)		CAT 6 S/FTP 4x2xAWG27/7 PIMF ISO/IEC 11801 & EN 50173-1 TIA/EIA 568B 2-1 HALOGEN FREE ***GIGABIT***		
(structure drawing)				
 wire AL flake braid jacket 1--white 2--blue 3--white 4--yellow 5--pink 6--green 7--white 8--brown				

Drawing:

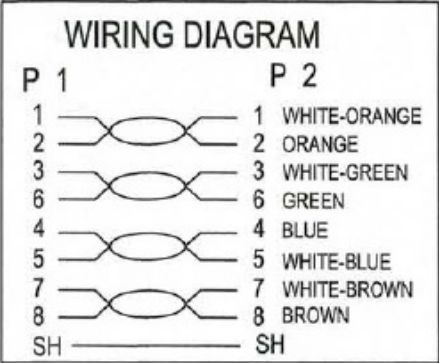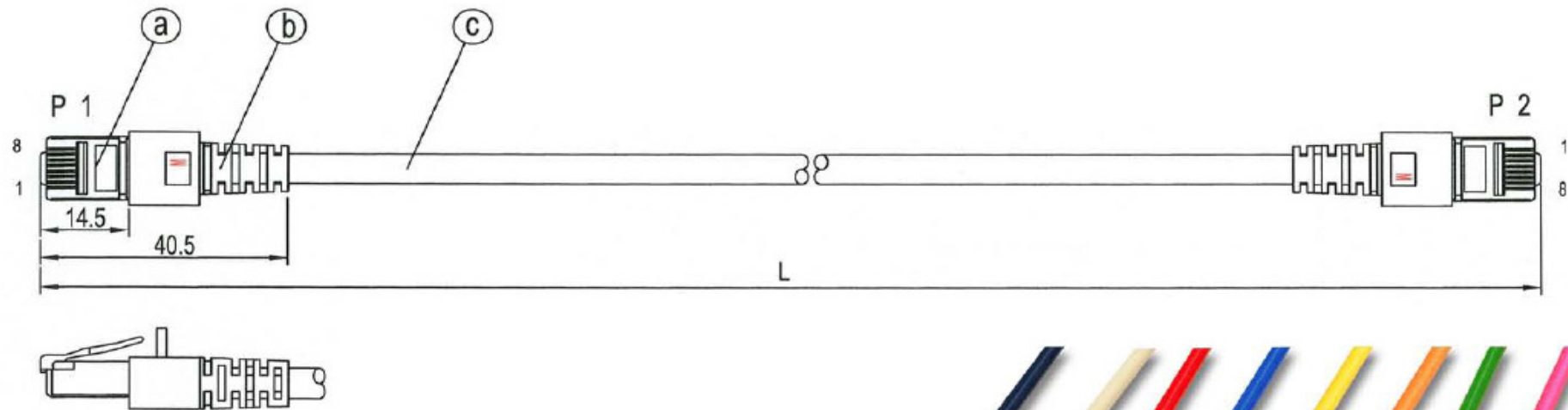


EFB NO.	COLOR
K5510.X	GREY
K5511.X	YELLOW
K5512.X	RED
K5513.X	BLUE
K5514.X	GREEN
K5515.X	BLACK
K5516.X	ORANGE
K5518.X	WHITE
K5519.X	MAGENTA

ALL LENGTH (L)	
500mm±5	7500mm±75
1000mm±10	10000mm±100
1500mm±15	15000mm±150
2000mm±20	20000mm±200
3000mm±30	25000mm±250
5000mm±50	30000mm±300

c	CABLE	SSTP CAT.6 27AWG stranded 4pairs cable LSZH OD=6.2mm Printing : CAT.6 S/FTP 4X2XAWG27/7 PIMF ISO/IEC 11801 & EN50173-1 TIA/EIA 568B.2-1 HALOGEN FREE ***GIGABIT***	L mm
b	OVERMOLD	PVC 75A / LENGTH IMPRINT ON BOOT	8 g
a	CONNECTOR	RJ45 8P8C'S SHIELDED GOLD PLATED 3-50u"	2 Pcs
NO.	MAT.NAME	DESCRIPTION	Q'TY

ROHS COMPLIANT

Impedance	Nom.100 Ohm±20%												
Frequency	MHZ	1	4	8	10	16	20	25	31.25	62.5	100	200	250
NEXT	DB	65	63.04	58.16	56.58	53.23	51.63	50.03	48.42	43.38	39.93	34.78	33.09
Attenuation	DB/100m	2.15	4.02	5.66	6.33	8.04	9.02	10.12	11.38	16.45	21.26	31.47	43.67
Returnloss	DB	19	19	19	19	17.98	17.49	17.01	16.53	14.02	12	8.98	7.99
ITEM													
DRAWING		SSTP 27AWG PATCH CORD											
UNIT	mm	SCALE		REV									
DRAWN BY		CHECK BY		APPRO BY		DATE							
						2006.11.26							

 

Contacting Basler Support Worldwide

Europe:

Basler AG
An der Strusbek 60 - 62
22926 Ahrensburg
Germany
Tel.: +49-4102-463-515
Fax.: +49-4102-463-599
bc.support.europe@baslerweb.com

Americas:

Basler, Inc.
855 Springdale Drive, Suite 203
Exton, PA 19341
U.S.A.
Tel.: +1-610-280-0171
Fax.: +1-610-280-7608
bc.support.usa@baslerweb.com

Asia:

Basler Asia Pte. Ltd
8 Boon Lay Way
03 - 03 Tradehub 21
Singapore 609964
Tel.: +65-6425-0472
Fax.: +65-6425-0473
bc.support.asia@baslerweb.com

www.baslerweb.com